

Star grips biopolymer similar to DIN 6336

Item description/product images



Description

Material:

Grip biopolymer.
Bush and screw steel.

Version:

Bush and screw trivalent blue passivated.
Natural beech with beech fibres or coloured black grey.


Advantages:

This biopolymer is manufactured entirely from renewable raw materials (oil free).
Conservation of finite fossil resources.
The wood fibres originate 100% from local, sustainably managed forests in Germany.

Features:

Excellent mechanical stability (certified with a minimum of 2x safety factor).
Biopolymer is suitable for recycling (comparable to thermoplastics).
Suitable for outdoor use (not biodegradable).
Excellent resistance to strong acids and lyes.
Short-term resistance to alcohol, fuel, mineral oil and grease.

Drawings

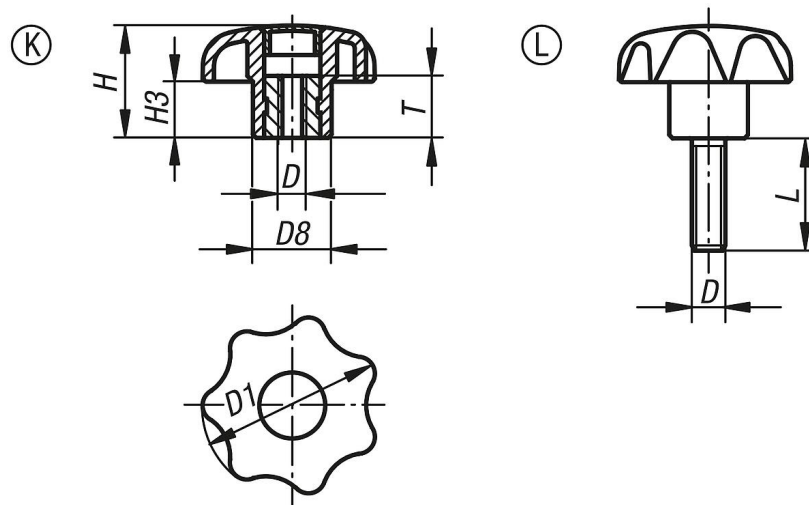

Overview of items

Star grips biopolymer similar to DIN 6336, internal thread

Order No.	Form	Main colour	D	D1	D8	H	H3	L	T
K0155.102051143	K	natural beech	M5	32	14	20	10	-	10
K0155.10206143	K	natural beech	M6	32	14	20	10	-	10
K0155.10208143	K	natural beech	M8	40	18	25	13	-	14
K0155.102081143	K	natural beech	M8	50	22	32	17	-	14
K0155.102101143	K	natural beech	M10	40	18	25	13	-	14
K0155.10210143	K	natural beech	M10	50	22	32	17	-	14
K0155.102121143	K	natural beech	M12	50	22	32	17	-	18
K0155.10205190	K	black grey RAL 7021	M5	32	14	20	10	-	10

Star grips biopolymer similar to DIN 6336

Overview of items

Order No.	Form	Main colour	D	D1	D8	H	H3	L	T
K0155.1020690	K	black grey RAL 7021	M6	32	14	20	10	-	10
K0155.1020890	K	black grey RAL 7021	M8	40	18	25	13	-	14
K0155.10208190	K	black grey RAL 7021	M8	50	22	32	17	-	14
K0155.10210190	K	black grey RAL 7021	M10	40	18	25	13	-	14
K0155.1021090	K	black grey RAL 7021	M10	50	22	32	17	-	14
K0155.10212190	K	black grey RAL 7021	M12	50	22	32	17	-	18
K0155.104061143X15	L	natural beech	M6	32	14	20	10	15	-
K0155.10408143X20	L	natural beech	M8	32	14	20	10	20	-
K0155.104081143X25	L	natural beech	M8	40	18	25	13	25	-
K0155.10410143X25	L	natural beech	M10	40	18	25	13	25	-
K0155.104101143X25	L	natural beech	M10	50	22	32	17	25	-
K0155.10412143X25	L	natural beech	M12	50	22	32	17	25	-
K0155.10406190X15	L	black grey RAL 7021	M6	32	14	20	10	15	-
K0155.1040890X20	L	black grey RAL 7021	M8	32	14	20	10	20	-
K0155.10408190X25	L	black grey RAL 7021	M8	40	18	25	13	25	-
K0155.1041090X25	L	black grey RAL 7021	M10	40	18	25	13	25	-
K0155.10410190X25	L	black grey RAL 7021	M10	50	22	32	17	25	-
K0155.1041290X25	L	black grey RAL 7021	M12	50	22	32	17	25	-