

Handles, Form E

Item description/product images



Description

Material:

Knobs thermoset PF 31.


Rod steel or stainless steel 1.4305.

Version:

Thermoset black, high-gloss polished.

Steel black oxidised, blue passivated or bright stainless steel

Drawings

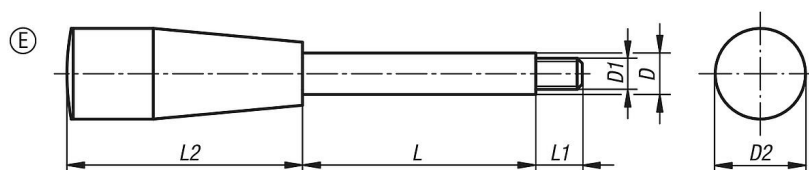

Overview of items

Order No.	Version	Surface finish body	Form	D	D1	D2	L	L1	L2
K0179.608X35	steel	black oxidised	E	8	M6	17	35	9	45
K0179.608X50	steel	black oxidised	E	8	M6	17	50	9	45
K0179.608X65	steel	black oxidised	E	8	M6	17	65	9	45
K0179.610X50	steel	black oxidised	E	10	M8	23	50	13	61
K0179.610X65	steel	black oxidised	E	10	M8	23	65	13	61
K0179.610X80	steel	black oxidised	E	10	M8	23	80	13	61
K0179.610X100	steel	black oxidised	E	10	M8	23	100	13	61
K0179.612X65	steel	black oxidised	E	12	M10	29	65	15	71
K0179.612X80	steel	black oxidised	E	12	M10	29	80	15	71
K0179.612X100	steel	black oxidised	E	12	M10	29	100	15	71
K0179.612X125	steel	black oxidised	E	12	M10	29	125	15	71
K0179.614X80	steel	black oxidised	E	14	M12	29	80	16	71
K0179.614X100	steel	black oxidised	E	14	M12	29	100	16	71
K0179.614X125	steel	black oxidised	E	14	M12	29	125	16	71
K0179.614X160	steel	black oxidised	E	14	M12	29	160	16	71
K0179.2608X35	steel	blue-passivated	E	8	M6	17	35	9	45
K0179.2608X50	steel	blue-passivated	E	8	M6	17	50	9	45
K0179.2608X65	steel	blue-passivated	E	8	M6	17	65	9	45
K0179.2610X50	steel	blue-passivated	E	10	M8	23	50	13	61
K0179.2610X65	steel	blue-passivated	E	10	M8	23	65	13	61
K0179.2610X80	steel	blue-passivated	E	10	M8	23	80	13	61
K0179.2610X100	steel	blue-passivated	E	10	M8	23	100	13	61
K0179.2612X65	steel	blue-passivated	E	12	M10	29	65	15	71
K0179.2612X80	steel	blue-passivated	E	12	M10	29	80	15	71
K0179.2612X100	steel	blue-passivated	E	12	M10	29	100	15	71
K0179.2612X125	steel	blue-passivated	E	12	M10	29	125	15	71
K0179.2614X80	steel	blue-passivated	E	14	M12	29	80	16	71
K0179.2614X100	steel	blue-passivated	E	14	M12	29	100	16	71
K0179.2614X125	steel	blue-passivated	E	14	M12	29	125	16	71
K0179.2614X160	steel	blue-passivated	E	14	M12	29	160	16	71
K0179.1608X35	stainless steel	bright	E	8	M6	17	35	9	45
K0179.1608X50	stainless steel	bright	E	8	M6	17	50	9	45
K0179.1608X65	stainless steel	bright	E	8	M6	17	65	9	45
K0179.1610X50	stainless steel	bright	E	10	M8	23	50	13	61
K0179.1610X65	stainless steel	bright	E	10	M8	23	65	13	61
K0179.1610X80	stainless steel	bright	E	10	M8	23	80	13	61
K0179.1610X100	stainless steel	bright	E	10	M8	23	100	13	61

Handles, Form E

Overview of items

Order No.	Version	Surface finish body	Form	D	D1	D2	L	L1	L2
K0179.1612X65	stainless steel	bright	E	12	M10	29	65	15	71
K0179.1612X80	stainless steel	bright	E	12	M10	29	80	15	71
K0179.1612X100	stainless steel	bright	E	12	M10	29	100	15	71
K0179.1612X125	stainless steel	bright	E	12	M10	29	125	15	71
K0179.1614X80	stainless steel	bright	E	14	M12	29	80	16	71
K0179.1614X100	stainless steel	bright	E	14	M12	29	100	16	71
K0179.1614X125	stainless steel	bright	E	14	M12	29	125	16	71
K0179.1614X160	stainless steel	bright	E	14	M12	29	160	16	71