

Hexagon nuts for EMC cable glands

Item description/product images



Description

Material:

Brass.

Version:


nickel-plated.

Note:

DIN EN 60423 hex nuts with metric thread. For securing EMC cable glands and accessories. With knife edge for cutting through paint or powder coatings to ensure optimum contact with the potential equaliser.

Temperature range:

-60°C to +200°C.

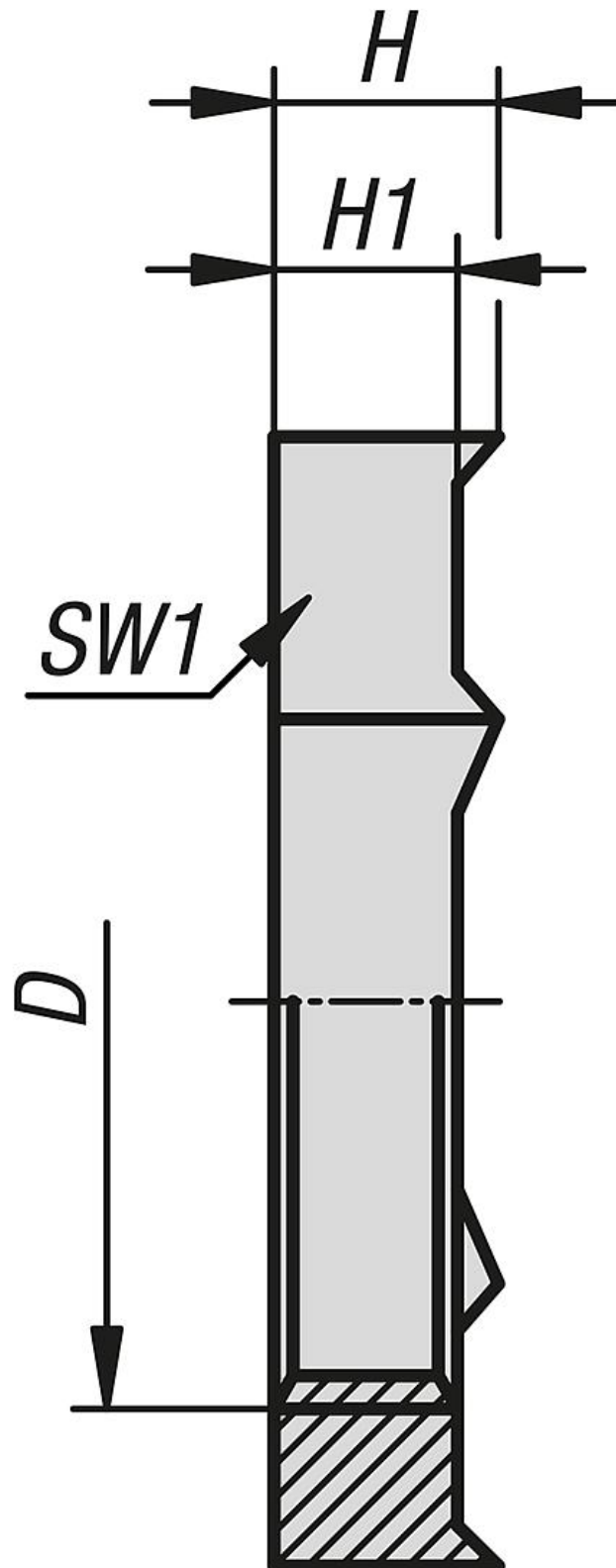

Hexagon nuts for EMC cable glands

Overview of items

Hexagon nuts for EMC cable glands

Order No.	D	H	H1	SW1	Max. tightening torque on SW1 Nm
K2251.11215	M12X1,5	3,5	2,8	15	3,5
K2251.11615	M16x1,5	3,5	2,8	19	3,5
K2251.12015	M20X1,5	3,7	3	24	3,5
K2251.12515	M25x1,5	4,2	3,5	30	6,7
K2251.13215	M32x1,5	4,7	4	36	12
K2251.14015	M40X1,5	5,7	5	46	13,5