

Palm grips aluminium, similar to DIN 6335

Item description/product images



Description

Material:

Aluminium.

Grub screw stainless steel 1.4305.

Pin stainless steel 1.4310.

Version:

Vibratory ground or ground and polished.

Grub screw and pin bright.

On request:

Blank palm grips (not tumbled).

Drawing reference:

Form A: blank

Form B: drilled through


Form C: blind hole

Form D: tapped and counterbored

Form E: tapped blind hole

Form L: external thread

Drawings

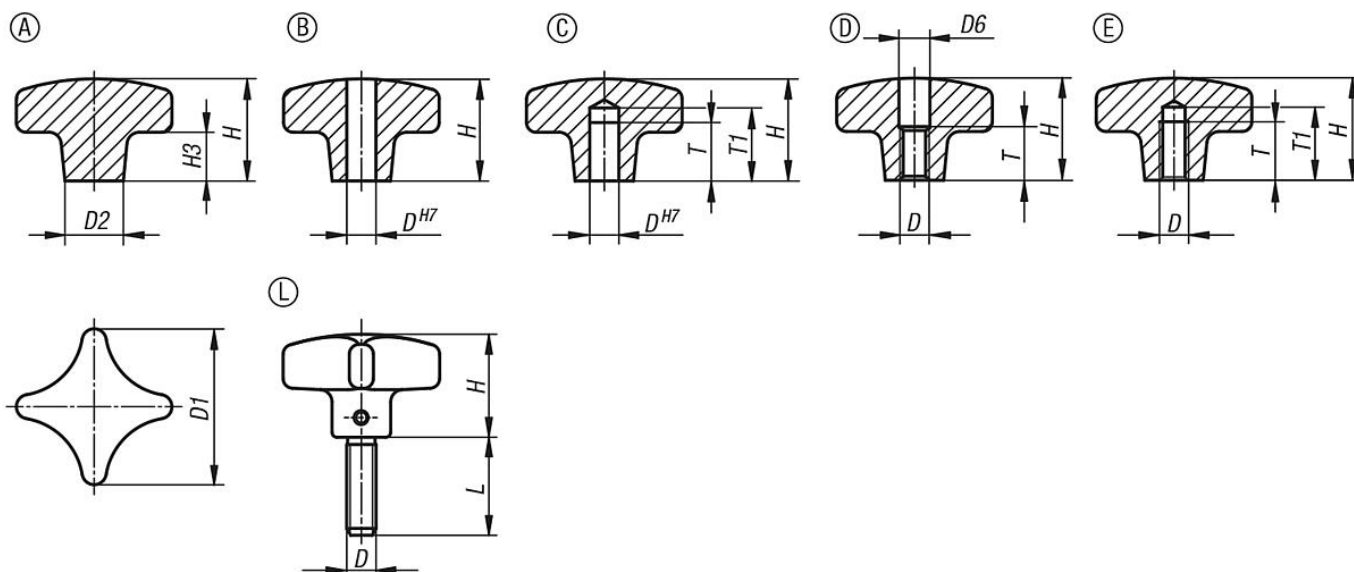

Overview of items

Palm grips aluminium, similar to DIN 6335

| Order No. | Form | Finish | D | D1 | D2 | D6 | H | H3 | L | T | T1 |
|--------------|------|---------|----|----|----|----|----|----|---|---|----|
| K0145.104008 | A | tumbled | - | 40 | 14 | - | 26 | 14 | - | - | - |
| K0145.105010 | A | tumbled | - | 50 | 18 | - | 34 | 20 | - | - | - |
| K0145.106312 | A | tumbled | - | 63 | 25 | - | 42 | 25 | - | - | - |
| K0145.108016 | A | tumbled | - | 80 | 25 | - | 52 | 30 | - | - | - |
| K0145.204008 | B | tumbled | 8 | 40 | 14 | - | 25 | - | - | - | - |
| K0145.205010 | B | tumbled | 10 | 50 | 18 | - | 32 | - | - | - | - |

Palm grips aluminium, similar to DIN 6335

Overview of items

| Order No. | Form | Finish | D | D1 | D2 | D6 | H | H3 | L | T | T1 |
|-----------------|------|----------|-----|----|----|------|----|----|----|----|----|
| K0145.206312 | B | tumbled | 12 | 63 | 25 | - | 40 | - | - | - | - |
| K0145.208016 | B | tumbled | 16 | 80 | 25 | - | 50 | - | - | - | - |
| K0145.2040082 | B | polished | 8 | 40 | 14 | - | 25 | - | - | - | - |
| K0145.2050102 | B | polished | 10 | 50 | 18 | - | 32 | - | - | - | - |
| K0145.2063122 | B | polished | 12 | 63 | 25 | - | 40 | - | - | - | - |
| K0145.2080162 | B | polished | 16 | 80 | 25 | - | 50 | - | - | - | - |
| K0145.304008 | C | tumbled | 8 | 40 | 14 | - | 25 | 14 | - | 15 | 18 |
| K0145.305010 | C | tumbled | 10 | 50 | 18 | - | 32 | 20 | - | 18 | 21 |
| K0145.306312 | C | tumbled | 12 | 63 | 25 | - | 40 | 25 | - | 22 | 25 |
| K0145.308016 | C | tumbled | 16 | 80 | 25 | - | 50 | 30 | - | 28 | 32 |
| K0145.3040082 | C | polished | 8 | 40 | 14 | - | 25 | 14 | - | 15 | 18 |
| K0145.3050102 | C | polished | 10 | 50 | 18 | - | 32 | 20 | - | 18 | 21 |
| K0145.3063122 | C | polished | 12 | 63 | 25 | - | 40 | 25 | - | 22 | 25 |
| K0145.3080162 | C | polished | 16 | 80 | 25 | - | 50 | 30 | - | 28 | 32 |
| K0145.404008 | D | tumbled | M8 | 40 | 14 | 8,4 | 25 | - | - | 15 | - |
| K0145.405010 | D | tumbled | M10 | 50 | 18 | 10,5 | 32 | - | - | 18 | - |
| K0145.406312 | D | tumbled | M12 | 63 | 25 | 13 | 40 | - | - | 22 | - |
| K0145.408016 | D | tumbled | M16 | 80 | 25 | 17 | 50 | - | - | 28 | - |
| K0145.4040082 | D | polished | M8 | 40 | 14 | 8,4 | 25 | - | - | 15 | - |
| K0145.4050102 | D | polished | M10 | 50 | 18 | 10,5 | 32 | - | - | 18 | - |
| K0145.4063122 | D | polished | M12 | 63 | 25 | 13 | 40 | - | - | 22 | - |
| K0145.4080162 | D | polished | M16 | 80 | 25 | 17 | 50 | - | - | 28 | - |
| K0145.504008 | E | tumbled | M8 | 40 | 14 | - | 25 | 14 | - | 15 | 18 |
| K0145.505010 | E | tumbled | M10 | 50 | 18 | - | 32 | 20 | - | 18 | 21 |
| K0145.506312 | E | tumbled | M12 | 63 | 25 | - | 40 | 25 | - | 22 | 25 |
| K0145.508016 | E | tumbled | M16 | 80 | 25 | - | 50 | 30 | - | 28 | 32 |
| K0145.5040082 | E | polished | M8 | 40 | 14 | - | 25 | 14 | - | 15 | 18 |
| K0145.5050102 | E | polished | M10 | 50 | 18 | - | 32 | 20 | - | 18 | 21 |
| K0145.5063122 | E | polished | M12 | 63 | 25 | - | 40 | 25 | - | 22 | 25 |
| K0145.5080162 | E | polished | M16 | 80 | 25 | - | 50 | 30 | - | 28 | 32 |
| K0145.604008X20 | L | tumbled | M8 | 40 | 14 | - | 25 | - | 20 | - | - |
| K0145.604008X25 | L | tumbled | M8 | 40 | 14 | - | 25 | - | 25 | - | - |
| K0145.604008X30 | L | tumbled | M8 | 40 | 14 | - | 25 | - | 30 | - | - |
| K0145.604008X40 | L | tumbled | M8 | 40 | 14 | - | 25 | - | 40 | - | - |
| K0145.604008X50 | L | tumbled | M8 | 40 | 14 | - | 25 | - | 50 | - | - |
| K0145.605010X20 | L | tumbled | M10 | 50 | 18 | - | 32 | - | 20 | - | - |
| K0145.605010X25 | L | tumbled | M10 | 50 | 18 | - | 32 | - | 25 | - | - |
| K0145.605010X30 | L | tumbled | M10 | 50 | 18 | - | 32 | - | 30 | - | - |
| K0145.605010X40 | L | tumbled | M10 | 50 | 18 | - | 32 | - | 40 | - | - |
| K0145.605010X50 | L | tumbled | M10 | 50 | 18 | - | 32 | - | 50 | - | - |
| K0145.606312X20 | L | tumbled | M12 | 63 | 25 | - | 40 | - | 20 | - | - |
| K0145.606312X30 | L | tumbled | M12 | 63 | 25 | - | 40 | - | 30 | - | - |
| K0145.606312X40 | L | tumbled | M12 | 63 | 25 | - | 40 | - | 40 | - | - |
| K0145.606312X50 | L | tumbled | M12 | 63 | 25 | - | 40 | - | 50 | - | - |