


Knurled knobs

Item description/product images

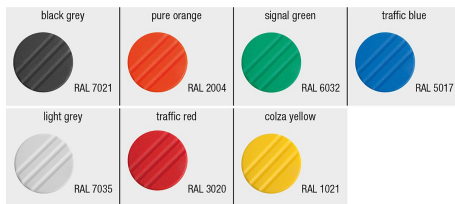

Description

Material:
Thermoplastic, black grey.
Bush steel.

Version:
Bush blue passivated

Note:
Available without graduations, with one scale line or with 20 graduations and 10 digits.


Δ Add the desired cap colour here. No colour code is required for black grey caps.

On request:
Special graduations.

Drawing reference:
Form A: without graduations
Form B: with one scale line
Form C: with standard graduations

1) Set screw for locking (by Form C between numbers 5 and 6)

Drawings

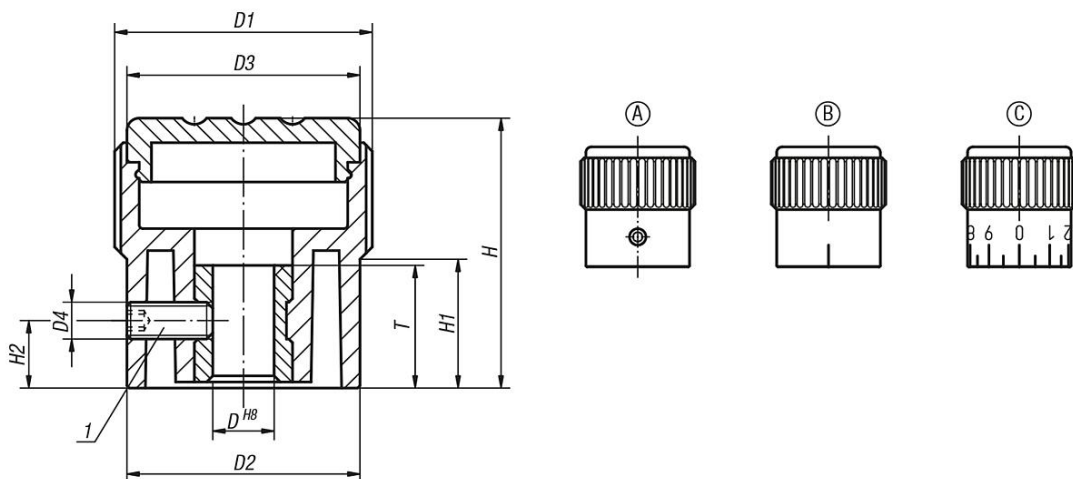

Overview of items

Knurled knobs

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	T
K0248.1105	A	black grey RAL 7021	5	21	19	19	M3	22	10,5	5	10
K0248.11051	A	orange RAL 2004	5	21	19	19	M3	22	10,5	5	10
K0248.11052	A	signal green RAL6032	5	21	19	19	M3	22	10,5	5	10
K0248.11053	A	blue RAL5017	5	21	19	19	M3	22	10,5	5	10
K0248.11055	A	light grey RAL 7035	5	21	19	19	M3	22	10,5	5	10
K0248.11056	A	traffic red RAL 3020	5	21	19	19	M3	22	10,5	5	10

Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	T
K0248.11057	A	colza yellow RAL 1021	5	21	19	19	M3	22	10,5	5	10
K0248.1206	A	black grey RAL 7021	6	26	23	23	M3	26	12	6	10
K0248.12061	A	orange RAL 2004	6	26	23	23	M3	26	12	6	10
K0248.12062	A	signal green RAL6032	6	26	23	23	M3	26	12	6	10
K0248.12063	A	blue RAL5017	6	26	23	23	M3	26	12	6	10
K0248.12065	A	light grey RAL 7035	6	26	23	23	M3	26	12	6	10
K0248.12066	A	traffic red RAL 3020	6	26	23	23	M3	26	12	6	10
K0248.12067	A	colza yellow RAL 1021	6	26	23	23	M3	26	12	6	10
K0248.1308	A	black grey RAL 7021	8	34	31	31	M4	36	17,5	7	14
K0248.13081	A	orange RAL 2004	8	34	31	31	M4	36	17,5	7	14
K0248.13082	A	signal green RAL6032	8	34	31	31	M4	36	17,5	7	14
K0248.13083	A	blue RAL5017	8	34	31	31	M4	36	17,5	7	14
K0248.13085	A	light grey RAL 7035	8	34	31	31	M4	36	17,5	7	14
K0248.13086	A	traffic red RAL 3020	8	34	31	31	M4	36	17,5	7	14
K0248.13087	A	colza yellow RAL 1021	8	34	31	31	M4	36	17,5	7	14
K0248.2105	B	black grey RAL 7021	5	21	19	19	M3	22	10,5	5	10
K0248.21051	B	orange RAL 2004	5	21	19	19	M3	22	10,5	5	10
K0248.21052	B	signal green RAL6032	5	21	19	19	M3	22	10,5	5	10
K0248.21053	B	blue RAL5017	5	21	19	19	M3	22	10,5	5	10
K0248.21055	B	light grey RAL 7035	5	21	19	19	M3	22	10,5	5	10
K0248.21056	B	traffic red RAL 3020	5	21	19	19	M3	22	10,5	5	10
K0248.21057	B	colza yellow RAL 1021	5	21	19	19	M3	22	10,5	5	10
K0248.2206	B	black grey RAL 7021	6	26	23	23	M3	26	12	6	10
K0248.22061	B	orange RAL 2004	6	26	23	23	M3	26	12	6	10
K0248.22062	B	signal green RAL6032	6	26	23	23	M3	26	12	6	10
K0248.22063	B	blue RAL5017	6	26	23	23	M3	26	12	6	10
K0248.22065	B	light grey RAL 7035	6	26	23	23	M3	26	12	6	10
K0248.22066	B	traffic red RAL 3020	6	26	23	23	M3	26	12	6	10
K0248.22067	B	colza yellow RAL 1021	6	26	23	23	M3	26	12	6	10
K0248.2308	B	black grey RAL 7021	8	34	31	31	M4	36	17,5	7	14
K0248.23081	B	orange RAL 2004	8	34	31	31	M4	36	17,5	7	14
K0248.23082	B	signal green RAL6032	8	34	31	31	M4	36	17,5	7	14
K0248.23083	B	blue RAL5017	8	34	31	31	M4	36	17,5	7	14
K0248.23085	B	light grey RAL 7035	8	34	31	31	M4	36	17,5	7	14
K0248.23086	B	traffic red RAL 3020	8	34	31	31	M4	36	17,5	7	14
K0248.23087	B	colza yellow RAL 1021	8	34	31	31	M4	36	17,5	7	14
K0248.3105	C	black grey RAL 7021	5	21	19	19	M3	22	10,5	5	10
K0248.31051	C	orange RAL 2004	5	21	19	19	M3	22	10,5	5	10
K0248.31052	C	signal green RAL6032	5	21	19	19	M3	22	10,5	5	10
K0248.31053	C	blue RAL5017	5	21	19	19	M3	22	10,5	5	10
K0248.31055	C	light grey RAL 7035	5	21	19	19	M3	22	10,5	5	10
K0248.31056	C	traffic red RAL 3020	5	21	19	19	M3	22	10,5	5	10
K0248.31057	C	colza yellow RAL 1021	5	21	19	19	M3	22	10,5	5	10
K0248.3206	C	black grey RAL 7021	6	26	23	23	M3	26	12	6	10
K0248.32061	C	orange RAL 2004	6	26	23	23	M3	26	12	6	10
K0248.32062	C	signal green RAL6032	6	26	23	23	M3	26	12	6	10
K0248.32063	C	blue RAL5017	6	26	23	23	M3	26	12	6	10
K0248.32065	C	light grey RAL 7035	6	26	23	23	M3	26	12	6	10
K0248.32066	C	traffic red RAL 3020	6	26	23	23	M3	26	12	6	10
K0248.32067	C	colza yellow RAL 1021	6	26	23	23	M3	26	12	6	10
K0248.3308	C	black grey RAL 7021	8	34	31	31	M4	36	17,5	7	14
K0248.33081	C	orange RAL 2004	8	34	31	31	M4	36	17,5	7	14
K0248.33082	C	signal green RAL6032	8	34	31	31	M4	36	17,5	7	14
K0248.33083	C	blue RAL5017	8	34	31	31	M4	36	17,5	7	14
K0248.33085	C	light grey RAL 7035	8	34	31	31	M4	36	17,5	7	14
K0248.33086	C	traffic red RAL 3020	8	34	31	31	M4	36	17,5	7	14
K0248.33087	C	colza yellow RAL 1021	8	34	31	31	M4	36	17,5	7	14

