

# Knurled knobs with arrow

## Item description/product images



black grey RAL 7021	pure orange RAL 2004	signal green RAL 6032	traffic blue RAL 5017
light grey RAL 7035	traffic red RAL 3020	colza yellow RAL 1021	

### Description

**Material:**

Knurled knob thermoplastic.  
Washer aluminium.

**Version:**

Knurled knob black grey.  
Washer, black anodised.

**Note:**


The arrow is engraved after anodizing. The set screw secures both the hub and the pressed-in washer. The H7 hole in the hub ensures a good tight fit on the shaft.

Δ Add the desired cap colour here. No colour code is required for black grey caps.

**Drawing reference:**

1) set screw

## Drawings

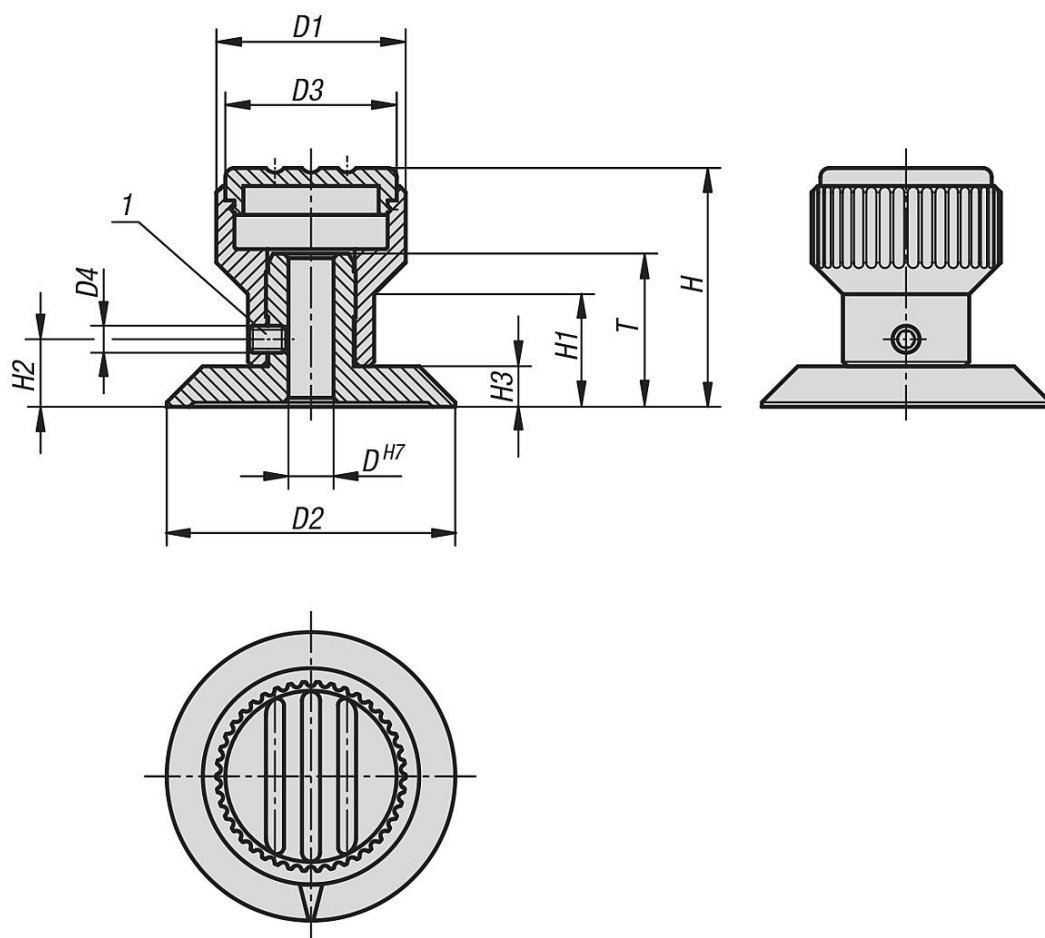

## Knurled knobs with arrow

### Overview of items

#### Knurled knobs with arrow

Order No.	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	T
K0249.105	black grey RAL 7021	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1051	orange RAL 2004	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1052	signal green RAL6032	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1053	blue RAL5017	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1055	light grey RAL 7035	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1056	traffic red RAL 3020	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1057	colza yellow RAL 1021	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.206	black grey RAL 7021	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2061	orange RAL 2004	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2062	signal green RAL6032	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2063	blue RAL5017	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2065	light grey RAL 7035	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2066	traffic red RAL 3020	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2067	colza yellow RAL 1021	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.308	black grey RAL 7021	8	34	52	31	M4	43	20	12	7	22
K0249.3081	orange RAL 2004	8	34	52	31	M4	43	20	12	7	22
K0249.3082	signal green RAL6032	8	34	52	31	M4	43	20	12	7	22
K0249.3083	blue RAL5017	8	34	52	31	M4	43	20	12	7	22
K0249.3085	light grey RAL 7035	8	34	52	31	M4	43	20	12	7	22
K0249.3086	traffic red RAL 3020	8	34	52	31	M4	43	20	12	7	22
K0249.3087	colza yellow RAL 1021	8	34	52	31	M4	43	20	12	7	22