


Mushroom knobs external thread

Item description/product images

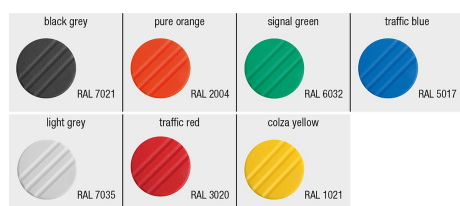

Description

Material:


Black thermoplastic.

Screw grade 5.8 steel or 1.4305 stainless steel.

Version:

Steel trivalent blue passivated, stainless steel bright.

Drawings

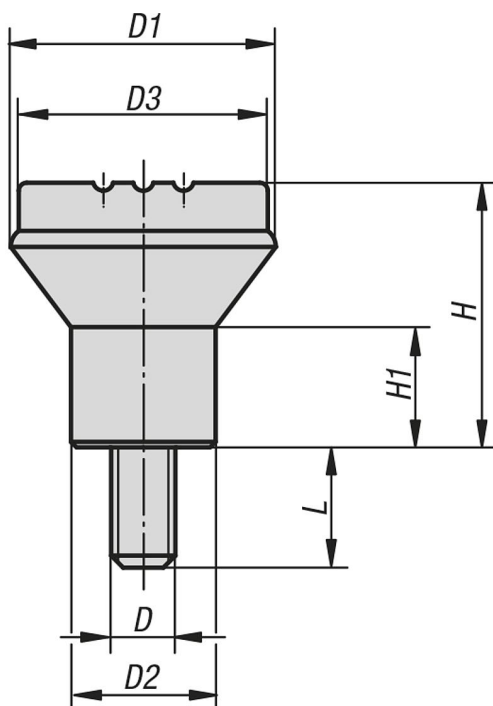

Overview of items

Mushroom knobs with external thread

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	L
K0251.04X10	steel	black grey RAL 7021	M4	21	12	19	21	10	10

Mushroom knobs external thread

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	L
K0251.041X10	steel	orange RAL 2004	M4	21	12	19	21	10	10
K0251.042X10	steel	signal green RAL6032	M4	21	12	19	21	10	10
K0251.043X10	steel	blue RAL5017	M4	21	12	19	21	10	10
K0251.045X10	steel	light grey RAL 7035	M4	21	12	19	21	10	10
K0251.046X10	steel	traffic red RAL 3020	M4	21	12	19	21	10	10
K0251.047X10	steel	colza yellow RAL 1021	M4	21	12	19	21	10	10
K0251.05X10	steel	black grey RAL 7021	M5	21	12	19	21	10	10
K0251.051X10	steel	orange RAL 2004	M5	21	12	19	21	10	10
K0251.052X10	steel	signal green RAL6032	M5	21	12	19	21	10	10
K0251.053X10	steel	blue RAL5017	M5	21	12	19	21	10	10
K0251.055X10	steel	light grey RAL 7035	M5	21	12	19	21	10	10
K0251.056X10	steel	traffic red RAL 3020	M5	21	12	19	21	10	10
K0251.057X10	steel	colza yellow RAL 1021	M5	21	12	19	21	10	10
K0251.06X15	steel	black grey RAL 7021	M6	25	14	23	25	12	15
K0251.061X15	steel	orange RAL 2004	M6	25	14	23	25	12	15
K0251.062X15	steel	signal green RAL6032	M6	25	14	23	25	12	15
K0251.063X15	steel	blue RAL5017	M6	25	14	23	25	12	15
K0251.065X15	steel	light grey RAL 7035	M6	25	14	23	25	12	15
K0251.066X15	steel	traffic red RAL 3020	M6	25	14	23	25	12	15
K0251.067X15	steel	colza yellow RAL 1021	M6	25	14	23	25	12	15
K0251.08X15	steel	black grey RAL 7021	M8	33	18	31	33	15	15
K0251.081X15	steel	orange RAL 2004	M8	33	18	31	33	15	15
K0251.082X15	steel	signal green RAL6032	M8	33	18	31	33	15	15
K0251.083X15	steel	blue RAL5017	M8	33	18	31	33	15	15
K0251.085X15	steel	light grey RAL 7035	M8	33	18	31	33	15	15
K0251.086X15	steel	traffic red RAL 3020	M8	33	18	31	33	15	15
K0251.087X15	steel	colza yellow RAL 1021	M8	33	18	31	33	15	15
K0251.004X10	stainless steel	black grey RAL 7021	M4	21	12	19	21	10	10
K0251.0041X10	stainless steel	orange RAL 2004	M4	21	12	19	21	10	10
K0251.0042X10	stainless steel	signal green RAL6032	M4	21	12	19	21	10	10
K0251.0043X10	stainless steel	blue RAL5017	M4	21	12	19	21	10	10
K0251.0045X10	stainless steel	light grey RAL 7035	M4	21	12	19	21	10	10
K0251.0046X10	stainless steel	traffic red RAL 3020	M4	21	12	19	21	10	10
K0251.0047X10	stainless steel	colza yellow RAL 1021	M4	21	12	19	21	10	10
K0251.005X10	stainless steel	black grey RAL 7021	M5	21	12	19	21	10	10
K0251.0051X10	stainless steel	orange RAL 2004	M5	21	12	19	21	10	10
K0251.0052X10	stainless steel	signal green RAL6032	M5	21	12	19	21	10	10
K0251.0053X10	stainless steel	blue RAL5017	M5	21	12	19	21	10	10
K0251.0055X10	stainless steel	light grey RAL 7035	M5	21	12	19	21	10	10
K0251.0056X10	stainless steel	traffic red RAL 3020	M5	21	12	19	21	10	10
K0251.0057X10	stainless steel	colza yellow RAL 1021	M5	21	12	19	21	10	10
K0251.006X15	stainless steel	black grey RAL 7021	M6	25	14	23	25	12	15
K0251.0061X15	stainless steel	orange RAL 2004	M6	25	14	23	25	12	15
K0251.0062X15	stainless steel	signal green RAL6032	M6	25	14	23	25	12	15
K0251.0063X15	stainless steel	blue RAL5017	M6	25	14	23	25	12	15
K0251.0065X15	stainless steel	light grey RAL 7035	M6	25	14	23	25	12	15
K0251.0066X15	stainless steel	traffic red RAL 3020	M6	25	14	23	25	12	15
K0251.0067X15	stainless steel	colza yellow RAL 1021	M6	25	14	23	25	12	15
K0251.008X15	stainless steel	black grey RAL 7021	M8	33	18	31	33	15	15
K0251.0081X15	stainless steel	orange RAL 2004	M8	33	18	31	33	15	15
K0251.0082X15	stainless steel	signal green RAL6032	M8	33	18	31	33	15	15
K0251.0083X15	stainless steel	blue RAL5017	M8	33	18	31	33	15	15
K0251.0085X15	stainless steel	light grey RAL 7035	M8	33	18	31	33	15	15
K0251.0086X15	stainless steel	traffic red RAL 3020	M8	33	18	31	33	15	15
K0251.0087X15	stainless steel	colza yellow RAL 1021	M8	33	18	31	33	15	15

