

## Knurled knobs

### Item description/product images



### Description

#### Material:

Grip black grey thermoplastic.  
 Bush brass or stainless steel 1.4305.  
 Screw steel 5.8 or stainless steel 1.4305.


#### Version:

Steel trivalent blue passivated.  
 Stainless steel, bright.

#### On request:

Other colours.

### Drawings

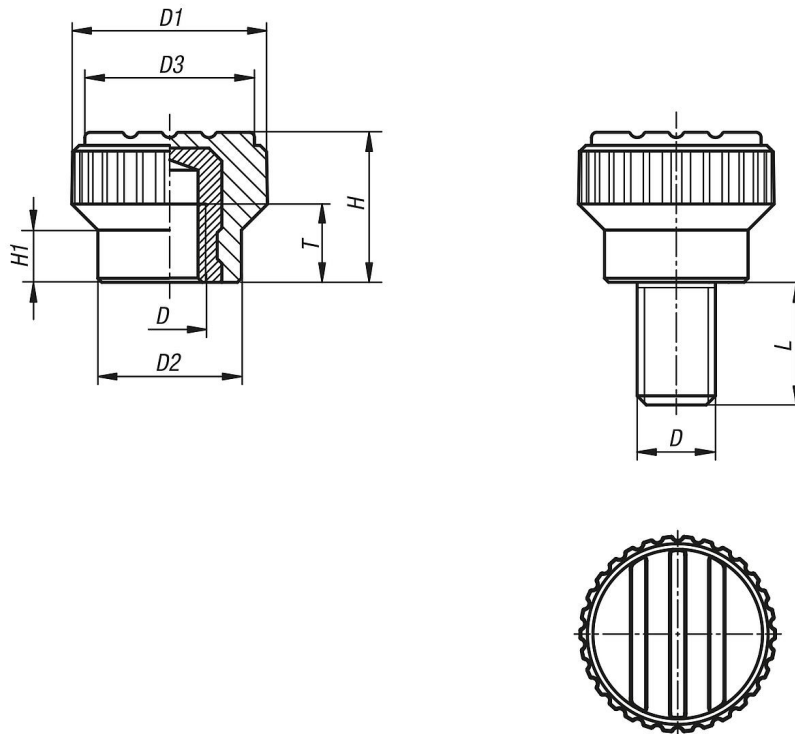

### Overview of items

#### Knurled knobs

Order No.	Thread type	Component material	D	D1	D2	D3	H	H1	T	L
K0110.003	internal thread	brass	M3	15	11	13	11,5	4,3	4,5	-
K0110.004	internal thread	brass	M4	15	11	13	11,5	4,3	6	-
K0110.005	internal thread	brass	M5	15	11	13	11,5	4,3	6	-
K0110.0003	internal thread	stainless steel	M3	15	11	13	11,5	4,3	4,5	-
K0110.0004	internal thread	stainless steel	M4	15	11	13	11,5	4,3	6	-
K0110.0005	internal thread	stainless steel	M5	15	11	13	11,5	4,3	6	-
K0110.003X8	external thread	steel	M3	15	11	13	11,5	4,3	-	8
K0110.003X10	external thread	steel	M3	15	11	13	11,5	4,3	-	10
K0110.003X12	external thread	steel	M3	15	11	13	11,5	4,3	-	12

## Knurled knobs

### Overview of items

Order No.	Thread type	Component material	D	D1	D2	D3	H	H1	T	L
K0110.003X15	external thread	steel	M3	15	11	13	11,5	4,3	-	15
K0110.004X8	external thread	steel	M4	15	11	13	11,5	4,3	-	8
K0110.004X10	external thread	steel	M4	15	11	13	11,5	4,3	-	10
K0110.004X12	external thread	steel	M4	15	11	13	11,5	4,3	-	12
K0110.004X15	external thread	steel	M4	15	11	13	11,5	4,3	-	15
K0110.005X10	external thread	steel	M5	15	11	13	11,5	4,3	-	10
K0110.005X12	external thread	steel	M5	15	11	13	11,5	4,3	-	12
K0110.005X15	external thread	steel	M5	15	11	13	11,5	4,3	-	15
K0110.005X20	external thread	steel	M5	15	11	13	11,5	4,3	-	20
K0110.006X10	external thread	steel	M6	15	11	13	11,5	4,3	-	10
K0110.006X15	external thread	steel	M6	15	11	13	11,5	4,3	-	15
K0110.006X20	external thread	steel	M6	15	11	13	11,5	4,3	-	20
K0110.006X25	external thread	steel	M6	15	11	13	11,5	4,3	-	25
K0110.0003X8	external thread	stainless steel	M3	15	11	13	11,5	4,3	-	8
K0110.0003X10	external thread	stainless steel	M3	15	11	13	11,5	4,3	-	10
K0110.0003X12	external thread	stainless steel	M3	15	11	13	11,5	4,3	-	12
K0110.0003X15	external thread	stainless steel	M3	15	11	13	11,5	4,3	-	15
K0110.0004X8	external thread	stainless steel	M4	15	11	13	11,5	4,3	-	8
K0110.0004X10	external thread	stainless steel	M4	15	11	13	11,5	4,3	-	10
K0110.0004X12	external thread	stainless steel	M4	15	11	13	11,5	4,3	-	12
K0110.0004X15	external thread	stainless steel	M4	15	11	13	11,5	4,3	-	15
K0110.0005X10	external thread	stainless steel	M5	15	11	13	11,5	4,3	-	10
K0110.0005X12	external thread	stainless steel	M5	15	11	13	11,5	4,3	-	12
K0110.0005X15	external thread	stainless steel	M5	15	11	13	11,5	4,3	-	15
K0110.0005X20	external thread	stainless steel	M5	15	11	13	11,5	4,3	-	20
K0110.0006X10	external thread	stainless steel	M6	15	11	13	11,5	4,3	-	10
K0110.0006X15	external thread	stainless steel	M6	15	11	13	11,5	4,3	-	15
K0110.0006X20	external thread	stainless steel	M6	15	11	13	11,5	4,3	-	20
K0110.0006X25	external thread	stainless steel	M6	15	11	13	11,5	4,3	-	25