

Dowel pins ISO 2338

Item description/product images



Description

Material:

Steel, stainless steel or stainless steel A4.

Version:


Steel, bright.

Stainless steel bright.

Note:

The dowel pins comply with ISO 2338.

Drawings

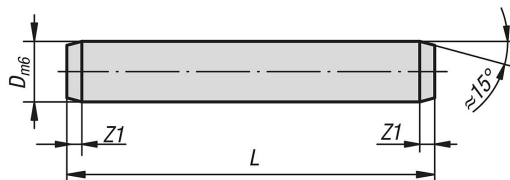

Overview of items

Dowel pins ISO 2338

Order No.	Main material	D	L	Z1
K2013.010X003	steel	1	3	0,2
K2013.010X004	steel	1	4	0,2
K2013.010X005	steel	1	5	0,2
K2013.010X006	steel	1	6	0,2
K2013.010X008	steel	1	8	0,2
K2013.010X010	steel	1	10	0,2
K2013.010X012	steel	1	12	0,2
K2013.015X003	steel	1,5	3	0,3
K2013.015X004	steel	1,5	4	0,3
K2013.015X005	steel	1,5	5	0,3
K2013.015X006	steel	1,5	6	0,3
K2013.015X008	steel	1,5	8	0,3
K2013.015X010	steel	1,5	10	0,3
K2013.015X012	steel	1,5	12	0,3
K2013.015X014	steel	1,5	14	0,3
K2013.015X016	steel	1,5	16	0,3
K2013.015X018	steel	1,5	18	0,3
K2013.015X020	steel	1,5	20	0,3
K2013.020X004	steel	2	4	0,35
K2013.020X005	steel	2	5	0,35
K2013.020X006	steel	2	6	0,35
K2013.020X008	steel	2	8	0,35
K2013.020X010	steel	2	10	0,35
K2013.020X012	steel	2	12	0,35
K2013.020X014	steel	2	14	0,35
K2013.020X016	steel	2	16	0,35
K2013.020X018	steel	2	18	0,35
K2013.020X020	steel	2	20	0,35
K2013.020X024	steel	2	24	0,35
K2013.020X028	steel	2	28	0,35
K2013.020X030	steel	2	30	0,35

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.025X006	steel	2,5	6	0,4
K2013.025X008	steel	2,5	8	0,4
K2013.025X010	steel	2,5	10	0,4
K2013.025X012	steel	2,5	12	0,4
K2013.025X014	steel	2,5	14	0,4
K2013.025X016	steel	2,5	16	0,4
K2013.025X018	steel	2,5	18	0,4
K2013.025X020	steel	2,5	20	0,4
K2013.025X024	steel	2,5	24	0,4
K2013.025X028	steel	2,5	28	0,4
K2013.025X032	steel	2,5	32	0,4
K2013.030X005	steel	3	5	0,5
K2013.030X006	steel	3	6	0,5
K2013.030X008	steel	3	8	0,5
K2013.030X010	steel	3	10	0,5
K2013.030X012	steel	3	12	0,5
K2013.030X014	steel	3	14	0,5
K2013.030X016	steel	3	16	0,5
K2013.030X018	steel	3	18	0,5
K2013.030X020	steel	3	20	0,5
K2013.030X024	steel	3	24	0,5
K2013.030X028	steel	3	28	0,5
K2013.030X030	steel	3	30	0,5
K2013.030X032	steel	3	32	0,5
K2013.030X036	steel	3	36	0,5
K2013.030X040	steel	3	40	0,5
K2013.030X045	steel	3	45	0,5
K2013.030X050	steel	3	50	0,5
K2013.040X005	steel	4	5	0,63
K2013.040X006	steel	4	6	0,63
K2013.040X008	steel	4	8	0,63
K2013.040X010	steel	4	10	0,63
K2013.040X012	steel	4	12	0,63
K2013.040X014	steel	4	14	0,63
K2013.040X016	steel	4	16	0,63
K2013.040X018	steel	4	18	0,63
K2013.040X020	steel	4	20	0,63
K2013.040X024	steel	4	24	0,63
K2013.040X028	steel	4	28	0,63
K2013.040X030	steel	4	30	0,63
K2013.040X032	steel	4	32	0,63
K2013.040X036	steel	4	36	0,63
K2013.040X040	steel	4	40	0,63
K2013.040X045	steel	4	45	0,63
K2013.040X050	steel	4	50	0,63
K2013.050X005	steel	5	5	0,8
K2013.050X006	steel	5	6	0,8
K2013.050X008	steel	5	8	0,8
K2013.050X010	steel	5	10	0,8
K2013.050X012	steel	5	12	0,8
K2013.050X014	steel	5	14	0,8
K2013.050X016	steel	5	16	0,8
K2013.050X018	steel	5	18	0,8
K2013.050X020	steel	5	20	0,8
K2013.050X022	steel	5	22	0,8
K2013.050X024	steel	5	24	0,8
K2013.050X028	steel	5	28	0,8
K2013.050X030	steel	5	30	0,8
K2013.050X032	steel	5	32	0,8
K2013.050X036	steel	5	36	0,8
K2013.050X040	steel	5	40	0,8
K2013.050X045	steel	5	45	0,8

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.050X050	steel	5	50	0,8
K2013.050X055	steel	5	55	0,8
K2013.050X060	steel	5	60	0,8
K2013.060X006	steel	6	6	1,2
K2013.060X008	steel	6	8	1,2
K2013.060X010	steel	6	10	1,2
K2013.060X012	steel	6	12	1,2
K2013.060X014	steel	6	14	1,2
K2013.060X016	steel	6	16	1,2
K2013.060X018	steel	6	18	1,2
K2013.060X020	steel	6	20	1,2
K2013.060X022	steel	6	22	1,2
K2013.060X024	steel	6	24	1,2
K2013.060X028	steel	6	28	1,2
K2013.060X030	steel	6	30	1,2
K2013.060X032	steel	6	32	1,2
K2013.060X036	steel	6	36	1,2
K2013.060X040	steel	6	40	1,2
K2013.060X045	steel	6	45	1,2
K2013.060X050	steel	6	50	1,2
K2013.060X060	steel	6	60	1,2
K2013.060X070	steel	6	70	1,2
K2013.060X080	steel	6	80	1,2
K2013.060X090	steel	6	90	1,2
K2013.060X100	steel	6	100	1,2
K2013.080X008	steel	8	8	1,6
K2013.080X010	steel	8	10	1,6
K2013.080X012	steel	8	12	1,6
K2013.080X014	steel	8	14	1,6
K2013.080X016	steel	8	16	1,6
K2013.080X018	steel	8	18	1,6
K2013.080X020	steel	8	20	1,6
K2013.080X022	steel	8	22	1,6
K2013.080X024	steel	8	24	1,6
K2013.080X026	steel	8	26	1,6
K2013.080X028	steel	8	28	1,6
K2013.080X030	steel	8	30	1,6
K2013.080X032	steel	8	32	1,6
K2013.080X036	steel	8	36	1,6
K2013.080X040	steel	8	40	1,6
K2013.080X045	steel	8	45	1,6
K2013.080X050	steel	8	50	1,6
K2013.080X055	steel	8	55	1,6
K2013.080X060	steel	8	60	1,6
K2013.080X070	steel	8	70	1,6
K2013.080X080	steel	8	80	1,6
K2013.080X090	steel	8	90	1,6
K2013.080X100	steel	8	100	1,6
K2013.100X010	steel	10	10	2
K2013.100X012	steel	10	12	2
K2013.100X014	steel	10	14	2
K2013.100X016	steel	10	16	2
K2013.100X018	steel	10	18	2
K2013.100X020	steel	10	20	2
K2013.100X024	steel	10	24	2
K2013.100X028	steel	10	28	2
K2013.100X030	steel	10	30	2
K2013.100X032	steel	10	32	2
K2013.100X036	steel	10	36	2
K2013.100X040	steel	10	40	2
K2013.100X045	steel	10	45	2
K2013.100X050	steel	10	50	2

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.100X055	steel	10	55	2
K2013.100X060	steel	10	60	2
K2013.100X065	steel	10	65	2
K2013.100X070	steel	10	70	2
K2013.100X080	steel	10	80	2
K2013.100X090	steel	10	90	2
K2013.100X100	steel	10	100	2
K2013.120X012	steel	12	12	2,5
K2013.120X014	steel	12	14	2,5
K2013.120X016	steel	12	16	2,5
K2013.120X018	steel	12	18	2,5
K2013.120X020	steel	12	20	2,5
K2013.120X024	steel	12	24	2,5
K2013.120X028	steel	12	28	2,5
K2013.120X030	steel	12	30	2,5
K2013.120X032	steel	12	32	2,5
K2013.120X036	steel	12	36	2,5
K2013.120X040	steel	12	40	2,5
K2013.120X045	steel	12	45	2,5
K2013.120X050	steel	12	50	2,5
K2013.120X055	steel	12	55	2,5
K2013.120X060	steel	12	60	2,5
K2013.120X070	steel	12	70	2,5
K2013.120X080	steel	12	80	2,5
K2013.120X090	steel	12	90	2,5
K2013.120X100	steel	12	100	2,5
K2013.160X020	steel	16	20	3
K2013.160X024	steel	16	24	3
K2013.160X028	steel	16	28	3
K2013.160X030	steel	16	30	3
K2013.160X032	steel	16	32	3
K2013.160X036	steel	16	36	3
K2013.160X040	steel	16	40	3
K2013.160X045	steel	16	45	3
K2013.160X050	steel	16	50	3
K2013.160X055	steel	16	55	3
K2013.160X060	steel	16	60	3
K2013.160X070	steel	16	70	3
K2013.160X080	steel	16	80	3
K2013.160X090	steel	16	90	3
K2013.160X100	steel	16	100	3
K2013.160X120	steel	16	120	3
K2013.200X024	steel	20	24	3,5
K2013.200X028	steel	20	28	3,5
K2013.200X030	steel	20	30	3,5
K2013.200X032	steel	20	32	3,5
K2013.200X036	steel	20	36	3,5
K2013.200X040	steel	20	40	3,5
K2013.200X045	steel	20	45	3,5
K2013.200X050	steel	20	50	3,5
K2013.200X055	steel	20	55	3,5
K2013.200X060	steel	20	60	3,5
K2013.200X070	steel	20	70	3,5
K2013.200X080	steel	20	80	3,5
K2013.200X100	steel	20	100	3,5
K2013.200X120	steel	20	120	3,5
K2013.250X040	steel	25	40	4
K2013.250X045	steel	25	45	4
K2013.250X050	steel	25	50	4
K2013.250X055	steel	25	55	4
K2013.250X060	steel	25	60	4
K2013.250X070	steel	25	70	4

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.250X080	steel	25	80	4
K2013.250X090	steel	25	90	4
K2013.250X100	steel	25	100	4
K2013.250X120	steel	25	120	4
K2013.300X040	steel	30	40	5
K2013.300X045	steel	30	45	5
K2013.300X050	steel	30	50	5
K2013.300X055	steel	30	55	5
K2013.300X060	steel	30	60	5
K2013.300X070	steel	30	70	5
K2013.300X080	steel	30	80	5
K2013.300X090	steel	30	90	5
K2013.300X100	steel	30	100	5
K2013.300X120	steel	30	120	5
K2013.1010X003	stainless steel	1	3	0,2
K2013.1010X004	stainless steel	1	4	0,2
K2013.1010X005	stainless steel	1	5	0,2
K2013.1010X006	stainless steel	1	6	0,2
K2013.1010X008	stainless steel	1	8	0,2
K2013.1010X010	stainless steel	1	10	0,2
K2013.1010X012	stainless steel	1	12	0,2
K2013.1015X003	stainless steel	1,5	3	0,3
K2013.1015X004	stainless steel	1,5	4	0,3
K2013.1015X005	stainless steel	1,5	5	0,3
K2013.1015X006	stainless steel	1,5	6	0,3
K2013.1015X008	stainless steel	1,5	8	0,3
K2013.1015X010	stainless steel	1,5	10	0,3
K2013.1015X012	stainless steel	1,5	12	0,3
K2013.1015X014	stainless steel	1,5	14	0,3
K2013.1015X016	stainless steel	1,5	16	0,3
K2013.1015X018	stainless steel	1,5	18	0,3
K2013.1015X020	stainless steel	1,5	20	0,3
K2013.1020X004	stainless steel	2	4	0,35
K2013.1020X005	stainless steel	2	5	0,35
K2013.1020X006	stainless steel	2	6	0,35
K2013.1020X008	stainless steel	2	8	0,35
K2013.1020X010	stainless steel	2	10	0,35
K2013.1020X012	stainless steel	2	12	0,35
K2013.1020X014	stainless steel	2	14	0,35
K2013.1020X016	stainless steel	2	16	0,35
K2013.1020X018	stainless steel	2	18	0,35
K2013.1020X020	stainless steel	2	20	0,35
K2013.1025X006	stainless steel	2,5	6	0,4
K2013.1025X008	stainless steel	2,5	8	0,4
K2013.1025X010	stainless steel	2,5	10	0,4
K2013.1025X012	stainless steel	2,5	12	0,4
K2013.1025X014	stainless steel	2,5	14	0,4
K2013.1025X016	stainless steel	2,5	16	0,4
K2013.1025X018	stainless steel	2,5	18	0,4
K2013.1025X020	stainless steel	2,5	20	0,4
K2013.1025X024	stainless steel	2,5	24	0,4
K2013.1030X005	stainless steel	3	5	0,5
K2013.1030X006	stainless steel	3	6	0,5
K2013.1030X008	stainless steel	3	8	0,5
K2013.1030X010	stainless steel	3	10	0,5
K2013.1030X012	stainless steel	3	12	0,5
K2013.1030X014	stainless steel	3	14	0,5
K2013.1030X016	stainless steel	3	16	0,5
K2013.1030X018	stainless steel	3	18	0,5
K2013.1030X020	stainless steel	3	20	0,5
K2013.1030X024	stainless steel	3	24	0,5
K2013.1030X028	stainless steel	3	28	0,5

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.1030X030	stainless steel	3	30	0,5
K2013.1030X032	stainless steel	3	32	0,5
K2013.1030X040	stainless steel	3	40	0,5
K2013.1030X045	stainless steel	3	45	0,5
K2013.1030X050	stainless steel	3	50	0,5
K2013.1030X060	stainless steel	3	60	0,5
K2013.1040X005	stainless steel	4	5	0,63
K2013.1040X006	stainless steel	4	6	0,63
K2013.1040X008	stainless steel	4	8	0,63
K2013.1040X010	stainless steel	4	10	0,63
K2013.1040X012	stainless steel	4	12	0,63
K2013.1040X014	stainless steel	4	14	0,63
K2013.1040X016	stainless steel	4	16	0,63
K2013.1040X018	stainless steel	4	18	0,63
K2013.1040X020	stainless steel	4	20	0,63
K2013.1040X024	stainless steel	4	24	0,63
K2013.1040X026	stainless steel	4	26	0,63
K2013.1040X028	stainless steel	4	28	0,63
K2013.1040X032	stainless steel	4	32	0,63
K2013.1040X036	stainless steel	4	36	0,63
K2013.1040X040	stainless steel	4	40	0,63
K2013.1040X050	stainless steel	4	50	0,63
K2013.1040X060	stainless steel	4	60	0,63
K2013.1050X005	stainless steel	5	5	0,8
K2013.1050X006	stainless steel	5	6	0,8
K2013.1050X008	stainless steel	5	8	0,8
K2013.1050X010	stainless steel	5	10	0,8
K2013.1050X012	stainless steel	5	12	0,8
K2013.1050X014	stainless steel	5	14	0,8
K2013.1050X016	stainless steel	5	16	0,8
K2013.1050X018	stainless steel	5	18	0,8
K2013.1050X020	stainless steel	5	20	0,8
K2013.1050X024	stainless steel	5	24	0,8
K2013.1050X028	stainless steel	5	28	0,8
K2013.1050X030	stainless steel	5	30	0,8
K2013.1050X032	stainless steel	5	32	0,8
K2013.1050X036	stainless steel	5	36	0,8
K2013.1050X040	stainless steel	5	40	0,8
K2013.1050X045	stainless steel	5	45	0,8
K2013.1050X050	stainless steel	5	50	0,8
K2013.1060X006	stainless steel	6	6	1,2
K2013.1060X008	stainless steel	6	8	1,2
K2013.1060X010	stainless steel	6	10	1,2
K2013.1060X012	stainless steel	6	12	1,2
K2013.1060X014	stainless steel	6	14	1,2
K2013.1060X016	stainless steel	6	16	1,2
K2013.1060X018	stainless steel	6	18	1,2
K2013.1060X020	stainless steel	6	20	1,2
K2013.1060X024	stainless steel	6	24	1,2
K2013.1060X028	stainless steel	6	28	1,2
K2013.1060X030	stainless steel	6	30	1,2
K2013.1060X032	stainless steel	6	32	1,2
K2013.1060X036	stainless steel	6	36	1,2
K2013.1060X040	stainless steel	6	40	1,2
K2013.1060X045	stainless steel	6	45	1,2
K2013.1060X050	stainless steel	6	50	1,2
K2013.1060X055	stainless steel	6	55	1,2
K2013.1060X060	stainless steel	6	60	1,2
K2013.1080X010	stainless steel	8	10	1,6
K2013.1080X012	stainless steel	8	12	1,6
K2013.1080X014	stainless steel	8	14	1,6
K2013.1080X016	stainless steel	8	16	1,6

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.1080X018	stainless steel	8	18	1,6
K2013.1080X020	stainless steel	8	20	1,6
K2013.1080X022	stainless steel	8	22	1,6
K2013.1080X024	stainless steel	8	24	1,6
K2013.1080X028	stainless steel	8	28	1,6
K2013.1080X030	stainless steel	8	30	1,6
K2013.1080X032	stainless steel	8	32	1,6
K2013.1080X036	stainless steel	8	36	1,6
K2013.1080X040	stainless steel	8	40	1,6
K2013.1080X045	stainless steel	8	45	1,6
K2013.1080X050	stainless steel	8	50	1,6
K2013.1080X055	stainless steel	8	55	1,6
K2013.1080X060	stainless steel	8	60	1,6
K2013.1080X070	stainless steel	8	70	1,6
K2013.1080X080	stainless steel	8	80	1,6
K2013.1080X090	stainless steel	8	90	1,6
K2013.1100X010	stainless steel	10	10	2
K2013.1100X012	stainless steel	10	12	2
K2013.1100X014	stainless steel	10	14	2
K2013.1100X016	stainless steel	10	16	2
K2013.1100X018	stainless steel	10	18	2
K2013.1100X020	stainless steel	10	20	2
K2013.1100X024	stainless steel	10	24	2
K2013.1100X028	stainless steel	10	28	2
K2013.1100X032	stainless steel	10	32	2
K2013.1100X036	stainless steel	10	36	2
K2013.1100X040	stainless steel	10	40	2
K2013.1100X045	stainless steel	10	45	2
K2013.1100X050	stainless steel	10	50	2
K2013.1100X055	stainless steel	10	55	2
K2013.1100X060	stainless steel	10	60	2
K2013.1100X070	stainless steel	10	70	2
K2013.1100X080	stainless steel	10	80	2
K2013.1100X090	stainless steel	10	90	2
K2013.1100X100	stainless steel	10	100	2
K2013.1120X016	stainless steel	12	16	2,5
K2013.1120X018	stainless steel	12	18	2,5
K2013.1120X020	stainless steel	12	20	2,5
K2013.1120X024	stainless steel	12	24	2,5
K2013.1120X030	stainless steel	12	30	2,5
K2013.1120X032	stainless steel	12	32	2,5
K2013.1120X040	stainless steel	12	40	2,5
K2013.1120X045	stainless steel	12	45	2,5
K2013.1120X050	stainless steel	12	50	2,5
K2013.1120X055	stainless steel	12	55	2,5
K2013.1120X060	stainless steel	12	60	2,5
K2013.1120X070	stainless steel	12	70	2,5
K2013.1120X080	stainless steel	12	80	2,5
K2013.1120X090	stainless steel	12	90	2,5
K2013.1120X100	stainless steel	12	100	2,5
K2013.1160X020	stainless steel	16	20	3
K2013.1160X024	stainless steel	16	24	3
K2013.1160X028	stainless steel	16	28	3
K2013.1160X032	stainless steel	16	32	3
K2013.1160X036	stainless steel	16	36	3
K2013.1160X040	stainless steel	16	40	3
K2013.1160X045	stainless steel	16	45	3
K2013.1160X050	stainless steel	16	50	3
K2013.1160X055	stainless steel	16	55	3
K2013.1160X060	stainless steel	16	60	3
K2013.1160X070	stainless steel	16	70	3
K2013.1160X080	stainless steel	16	80	3

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.1160X090	stainless steel	16	90	3
K2013.1160X100	stainless steel	16	100	3
K2013.6010X003	stainless steel A4	1	3	0,2
K2013.6010X004	stainless steel A4	1	4	0,2
K2013.6010X005	stainless steel A4	1	5	0,2
K2013.6010X006	stainless steel A4	1	6	0,2
K2013.6010X008	stainless steel A4	1	8	0,2
K2013.6010X010	stainless steel A4	1	10	0,2
K2013.6010X012	stainless steel A4	1	12	0,2
K2013.6015X004	stainless steel A4	1,5	4	0,3
K2013.6015X005	stainless steel A4	1,5	5	0,3
K2013.6015X006	stainless steel A4	1,5	6	0,3
K2013.6015X008	stainless steel A4	1,5	8	0,3
K2013.6015X010	stainless steel A4	1,5	10	0,3
K2013.6015X012	stainless steel A4	1,5	12	0,3
K2013.6015X014	stainless steel A4	1,5	14	0,3
K2013.6015X016	stainless steel A4	1,5	16	0,3
K2013.6015X018	stainless steel A4	1,5	18	0,3
K2013.6015X020	stainless steel A4	1,5	20	0,3
K2013.6020X005	stainless steel A4	2	5	0,35
K2013.6020X006	stainless steel A4	2	6	0,35
K2013.6020X008	stainless steel A4	2	8	0,35
K2013.6020X010	stainless steel A4	2	10	0,35
K2013.6020X012	stainless steel A4	2	12	0,35
K2013.6020X014	stainless steel A4	2	14	0,35
K2013.6020X016	stainless steel A4	2	16	0,35
K2013.6020X018	stainless steel A4	2	18	0,35
K2013.6020X020	stainless steel A4	2	20	0,35
K2013.6020X024	stainless steel A4	2	24	0,35
K2013.6025X006	stainless steel A4	2,5	6	0,4
K2013.6025X008	stainless steel A4	2,5	8	0,4
K2013.6025X010	stainless steel A4	2,5	10	0,4
K2013.6025X012	stainless steel A4	2,5	12	0,4
K2013.6025X014	stainless steel A4	2,5	14	0,4
K2013.6025X016	stainless steel A4	2,5	16	0,4
K2013.6025X018	stainless steel A4	2,5	18	0,4
K2013.6025X020	stainless steel A4	2,5	20	0,4
K2013.6025X024	stainless steel A4	2,5	24	0,4
K2013.6030X005	stainless steel A4	3	5	0,5
K2013.6030X006	stainless steel A4	3	6	0,5
K2013.6030X008	stainless steel A4	3	8	0,5
K2013.6030X010	stainless steel A4	3	10	0,5
K2013.6030X012	stainless steel A4	3	12	0,5
K2013.6030X014	stainless steel A4	3	14	0,5
K2013.6030X016	stainless steel A4	3	16	0,5
K2013.6030X018	stainless steel A4	3	18	0,5
K2013.6030X020	stainless steel A4	3	20	0,5
K2013.6030X024	stainless steel A4	3	24	0,5
K2013.6030X028	stainless steel A4	3	28	0,5
K2013.6030X030	stainless steel A4	3	30	0,5
K2013.6030X032	stainless steel A4	3	32	0,5
K2013.6040X006	stainless steel A4	4	6	0,63
K2013.6040X008	stainless steel A4	4	8	0,63
K2013.6040X010	stainless steel A4	4	10	0,63
K2013.6040X012	stainless steel A4	4	12	0,63
K2013.6040X014	stainless steel A4	4	14	0,63
K2013.6040X016	stainless steel A4	4	16	0,63
K2013.6040X018	stainless steel A4	4	18	0,63
K2013.6040X020	stainless steel A4	4	20	0,63
K2013.6040X024	stainless steel A4	4	24	0,63
K2013.6040X028	stainless steel A4	4	28	0,63
K2013.6040X030	stainless steel A4	4	30	0,63

Dowel pins ISO 2338

Overview of items

Order No.	Main material	D	L	Z1
K2013.6040X032	stainless steel A4	4	32	0,63
K2013.6040X036	stainless steel A4	4	36	0,63
K2013.6040X040	stainless steel A4	4	40	0,63
K2013.6050X006	stainless steel A4	5	6	0,8
K2013.6050X008	stainless steel A4	5	8	0,8
K2013.6050X010	stainless steel A4	5	10	0,8
K2013.6050X012	stainless steel A4	5	12	0,8
K2013.6050X014	stainless steel A4	5	14	0,8
K2013.6050X016	stainless steel A4	5	16	0,8
K2013.6050X018	stainless steel A4	5	18	0,8
K2013.6050X020	stainless steel A4	5	20	0,8
K2013.6050X024	stainless steel A4	5	24	0,8
K2013.6050X028	stainless steel A4	5	28	0,8
K2013.6050X030	stainless steel A4	5	30	0,8
K2013.6050X032	stainless steel A4	5	32	0,8
K2013.6050X036	stainless steel A4	5	36	0,8
K2013.6050X040	stainless steel A4	5	40	0,8
K2013.6050X045	stainless steel A4	5	45	0,8
K2013.6050X050	stainless steel A4	5	50	0,8
K2013.6060X008	stainless steel A4	6	8	1,2
K2013.6060X010	stainless steel A4	6	10	1,2
K2013.6060X012	stainless steel A4	6	12	1,2
K2013.6060X014	stainless steel A4	6	14	1,2
K2013.6060X016	stainless steel A4	6	16	1,2
K2013.6060X018	stainless steel A4	6	18	1,2
K2013.6060X020	stainless steel A4	6	20	1,2
K2013.6060X024	stainless steel A4	6	24	1,2
K2013.6060X028	stainless steel A4	6	28	1,2
K2013.6060X032	stainless steel A4	6	32	1,2
K2013.6060X036	stainless steel A4	6	36	1,2
K2013.6060X040	stainless steel A4	6	40	1,2
K2013.6060X045	stainless steel A4	6	45	1,2
K2013.6060X050	stainless steel A4	6	50	1,2
K2013.6060X055	stainless steel A4	6	55	1,2
K2013.6060X060	stainless steel A4	6	60	1,2
K2013.6080X010	stainless steel A4	8	10	1,6
K2013.6080X012	stainless steel A4	8	12	1,6
K2013.6080X014	stainless steel A4	8	14	1,6
K2013.6080X016	stainless steel A4	8	16	1,6
K2013.6080X018	stainless steel A4	8	18	1,6
K2013.6080X020	stainless steel A4	8	20	1,6
K2013.6080X024	stainless steel A4	8	24	1,6
K2013.6080X028	stainless steel A4	8	28	1,6
K2013.6080X030	stainless steel A4	8	30	1,6
K2013.6080X032	stainless steel A4	8	32	1,6
K2013.6080X036	stainless steel A4	8	36	1,6
K2013.6080X040	stainless steel A4	8	40	1,6
K2013.6080X045	stainless steel A4	8	45	1,6
K2013.6080X050	stainless steel A4	8	50	1,6
K2013.6080X060	stainless steel A4	8	60	1,6
K2013.6080X070	stainless steel A4	8	70	1,6
K2013.6080X080	stainless steel A4	8	80	1,6
K2013.6100X012	stainless steel A4	10	12	2
K2013.6100X014	stainless steel A4	10	14	2
K2013.6100X016	stainless steel A4	10	16	2
K2013.6100X018	stainless steel A4	10	18	2
K2013.6100X020	stainless steel A4	10	20	2
K2013.6100X024	stainless steel A4	10	24	2
K2013.6100X028	stainless steel A4	10	28	2
K2013.6100X030	stainless steel A4	10	30	2
K2013.6100X032	stainless steel A4	10	32	2
K2013.6100X036	stainless steel A4	10	36	2

Overview of items

Order No.	Main material	D	L	Z1
K2013.6100X040	stainless steel A4	10	40	2
K2013.6100X050	stainless steel A4	10	50	2
K2013.6100X055	stainless steel A4	10	55	2
K2013.6100X060	stainless steel A4	10	60	2
K2013.6100X070	stainless steel A4	10	70	2
K2013.6100X080	stainless steel A4	10	80	2
K2013.6100X090	stainless steel A4	10	90	2
K2013.6100X100	stainless steel A4	10	100	2
K2013.6120X014	stainless steel A4	12	14	2,5
K2013.6120X016	stainless steel A4	12	16	2,5
K2013.6120X018	stainless steel A4	12	18	2,5
K2013.6120X020	stainless steel A4	12	20	2,5
K2013.6120X024	stainless steel A4	12	24	2,5
K2013.6120X028	stainless steel A4	12	28	2,5
K2013.6120X040	stainless steel A4	12	40	2,5
K2013.6120X050	stainless steel A4	12	50	2,5
K2013.6120X060	stainless steel A4	12	60	2,5
K2013.6120X070	stainless steel A4	12	70	2,5
K2013.6120X080	stainless steel A4	12	80	2,5
K2013.6120X090	stainless steel A4	12	90	2,5
K2013.6120X100	stainless steel A4	12	100	2,5
K2013.6160X020	stainless steel A4	16	20	3
K2013.6160X024	stainless steel A4	16	24	3
K2013.6160X028	stainless steel A4	16	28	3
K2013.6160X032	stainless steel A4	16	32	3
K2013.6160X036	stainless steel A4	16	36	3
K2013.6160X040	stainless steel A4	16	40	3
K2013.6160X045	stainless steel A4	16	45	3
K2013.6160X050	stainless steel A4	16	50	3
K2013.6160X055	stainless steel A4	16	55	3
K2013.6160X060	stainless steel A4	16	60	3
K2013.6160X070	stainless steel A4	16	70	3
K2013.6160X080	stainless steel A4	16	80	3
K2013.6160X090	stainless steel A4	16	90	3
K2013.6160X100	stainless steel A4	16	100	3