

Star grips similar to DIN 6336

Item description/product images



examples of grip cap designs



Description


Material:
Black thermoplastic.
Bush and screw steel.

Version:
Bush and screw trivalent blue passivated.

On request:
Other colours or designs, such as company logo.

Drawing reference:
Form D: tapped bush without cap
Form G: without bush
Form H: with reamed bush
Form K: tapped bush with cap
Form L: external thread
Form S: hexagon

Drawings

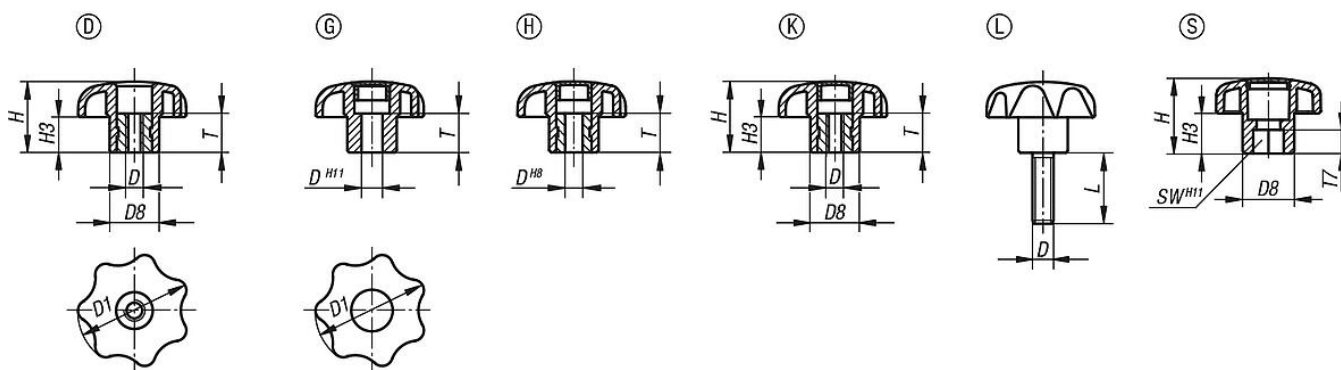

Overview of items

Star grips similar to DIN 6336

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|------------|------|----------------------|-----|----|----|----|----|---|----|----|----|
| K0155.504 | D | - | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.505 | D | - | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.5061 | D | - | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.5051 | D | - | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.506 | D | - | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.508 | D | - | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.5101 | D | - | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.5081 | D | - | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.510 | D | - | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.5121 | D | - | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| K0155.5102 | D | - | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.512 | D | - | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.516 | D | - | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.305 | G | jet black | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.3055 | G | light grey RAL 7035 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.3056 | G | traffic red RAL 3020 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|-------------|------|-----------------------|----|----|----|----|----|---|----|----|----|
| K0155.3057 | G | colza yellow RAL 1021 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.306 | G | jet black | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.3065 | G | light grey RAL 7035 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.3066 | G | traffic red RAL 3020 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.3067 | G | colza yellow RAL 1021 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.308 | G | jet black | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.3085 | G | light grey RAL 7035 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.3086 | G | traffic red RAL 3020 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.3087 | G | colza yellow RAL 1021 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.310 | G | jet black | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.3105 | G | light grey RAL 7035 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.3106 | G | traffic red RAL 3020 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.3107 | G | colza yellow RAL 1021 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.312 | G | jet black | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.3125 | G | light grey RAL 7035 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.3126 | G | traffic red RAL 3020 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.3127 | G | colza yellow RAL 1021 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.105 | H | jet black | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.1055 | H | light grey RAL 7035 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.1056 | H | traffic red RAL 3020 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.1057 | H | colza yellow RAL 1021 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.106 | H | jet black | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.1065 | H | light grey RAL 7035 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.1066 | H | traffic red RAL 3020 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.1067 | H | colza yellow RAL 1021 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.108 | H | jet black | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.1085 | H | light grey RAL 7035 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.1086 | H | traffic red RAL 3020 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.1087 | H | colza yellow RAL 1021 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.110 | H | jet black | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.1105 | H | light grey RAL 7035 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.1106 | H | traffic red RAL 3020 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.1107 | H | colza yellow RAL 1021 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.1101 | H | jet black | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.11015 | H | light grey RAL 7035 | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.11016 | H | traffic red RAL 3020 | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.11017 | H | colza yellow RAL 1021 | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.112 | H | jet black | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.1125 | H | light grey RAL 7035 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.1126 | H | traffic red RAL 3020 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.1127 | H | colza yellow RAL 1021 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.204 | K | jet black | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2045 | K | light grey RAL 7035 | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2046 | K | traffic red RAL 3020 | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2047 | K | colza yellow RAL 1021 | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.205 | K | jet black | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2055 | K | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2056 | K | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2057 | K | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2061 | K | jet black | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.20615 | K | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.20616 | K | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.20617 | K | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| K0155.2051 | K | jet black | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.20515 | K | light grey RAL 7035 | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.20516 | K | traffic red RAL 3020 | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.20517 | K | colza yellow RAL 1021 | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.206 | K | jet black | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.2065 | K | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.2066 | K | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.2067 | K | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| K0155.208 | K | jet black | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|---------------|------|-----------------------|-----|----|----|----|----|----|----|----|----|
| K0155.2085 | K | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.2086 | K | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.2087 | K | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.2101 | K | jet black | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.21015 | K | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.21016 | K | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.21017 | K | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| K0155.2081 | K | jet black | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.20815 | K | light grey RAL 7035 | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.20816 | K | traffic red RAL 3020 | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.20817 | K | colza yellow RAL 1021 | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.210 | K | jet black | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.2105 | K | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.2106 | K | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.2107 | K | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| K0155.2121 | K | jet black | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| K0155.21215 | K | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| K0155.21216 | K | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| K0155.21217 | K | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| K0155.2102 | K | jet black | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.21025 | K | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.21026 | K | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.21027 | K | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| K0155.212 | K | jet black | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.2125 | K | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.2126 | K | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.2127 | K | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.216 | K | jet black | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.2165 | K | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.2166 | K | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.2167 | K | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| K0155.405X10 | L | jet black | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.4055X10 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.4056X10 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.4057X10 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.405X15 | L | jet black | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.4055X15 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.4056X15 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.4057X15 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.405X20 | L | jet black | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.4055X20 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.4056X20 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.4057X20 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.405X25 | L | jet black | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.4055X25 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.4056X25 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.4057X25 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.405X30 | L | jet black | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.4055X30 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.4056X30 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.4057X30 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.405X35 | L | jet black | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.4055X35 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.4056X35 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.4057X35 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.405X40 | L | jet black | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.4055X40 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.4056X40 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.4057X40 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.405X45 | L | jet black | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.4055X45 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.4056X45 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|----|----|----|----|----|----|----|---|----|
| K0155.4057X45 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.405X50 | L | jet black | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.4055X50 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.4056X50 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.4057X50 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.405X60 | L | jet black | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4055X60 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4056X60 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4057X60 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.406X10 | L | jet black | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.4065X10 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.4066X10 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.4067X10 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| K0155.406X15 | L | jet black | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.4065X15 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.4066X15 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.4067X15 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| K0155.406X20 | L | jet black | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.4065X20 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.4066X20 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.4067X20 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| K0155.406X25 | L | jet black | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.4065X25 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.4066X25 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.4067X25 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| K0155.406X30 | L | jet black | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.4065X30 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.4066X30 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.4067X30 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| K0155.406X35 | L | jet black | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.4065X35 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.4066X35 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.4067X35 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| K0155.406X40 | L | jet black | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.4065X40 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.4066X40 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.4067X40 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| K0155.406X45 | L | jet black | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.4065X45 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.4066X45 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.4067X45 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| K0155.406X50 | L | jet black | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.4065X50 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.4066X50 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.4067X50 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| K0155.406X60 | L | jet black | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4065X60 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4066X60 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4067X60 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| K0155.4061X10 | L | jet black | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| K0155.40615X10 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| K0155.40616X10 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| K0155.40617X10 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| K0155.4061X15 | L | jet black | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.40615X15 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.40616X15 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.40617X15 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.4061X20 | L | jet black | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.40615X20 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.40616X20 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.40617X20 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.4061X25 | L | jet black | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|----|----|----|----|----|----|----|---|----|
| K0155.40615X25 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.40616X25 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.40617X25 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.4061X30 | L | jet black | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.40615X30 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.40616X30 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.40617X30 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.4061X35 | L | jet black | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.40615X35 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.40616X35 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.40617X35 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.4061X40 | L | jet black | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.40615X40 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.40616X40 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.40617X40 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.4061X45 | L | jet black | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.40615X45 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.40616X45 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.40617X45 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.4061X50 | L | jet black | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.40615X50 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.40616X50 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.40617X50 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.4061X60 | L | jet black | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.40615X60 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.40616X60 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.40617X60 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.408X15 | L | jet black | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.4085X15 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.4086X15 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.4087X15 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| K0155.408X20 | L | jet black | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.4085X20 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.4086X20 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.4087X20 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| K0155.408X25 | L | jet black | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.4085X25 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.4086X25 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.4087X25 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| K0155.408X30 | L | jet black | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.4085X30 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.4086X30 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.4087X30 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| K0155.408X35 | L | jet black | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.4085X35 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.4086X35 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.4087X35 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| K0155.408X40 | L | jet black | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.4085X40 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.4086X40 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.4087X40 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| K0155.408X45 | L | jet black | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.4085X45 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.4086X45 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.4087X45 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| K0155.408X50 | L | jet black | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.4085X50 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.4086X50 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.4087X50 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| K0155.408X60 | L | jet black | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.4085X60 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.4086X60 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| K0155.4087X60 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| K0155.4081X15 | L | jet black | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.40815X15 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.40816X15 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.40817X15 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.4081X20 | L | jet black | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.40815X20 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.40816X20 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.40817X20 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.4081X25 | L | jet black | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.40815X25 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.40816X25 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.40817X25 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.4081X30 | L | jet black | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.40815X30 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.40816X30 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.40817X30 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.4081X35 | L | jet black | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.40815X35 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.40816X35 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.40817X35 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.4081X40 | L | jet black | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.40815X40 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.40816X40 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.40817X40 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.4081X45 | L | jet black | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.40815X45 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.40816X45 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.40817X45 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.4081X50 | L | jet black | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.40815X50 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.40816X50 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.40817X50 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.4081X60 | L | jet black | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.40815X60 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.40816X60 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.40817X60 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.410X15 | L | jet black | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.4105X15 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.4106X15 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.4107X15 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| K0155.410X20 | L | jet black | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.4105X20 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.4106X20 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.4107X20 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| K0155.410X25 | L | jet black | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.4105X25 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.4106X25 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.4107X25 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| K0155.410X30 | L | jet black | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.4105X30 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.4106X30 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.4107X30 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| K0155.410X35 | L | jet black | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.4105X35 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.4106X35 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.4107X35 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| K0155.410X40 | L | jet black | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.4105X40 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.4106X40 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.4107X40 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| K0155.410X45 | L | jet black | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| K0155.4105X45 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.4106X45 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.4107X45 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| K0155.410X50 | L | jet black | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.4105X50 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.4106X50 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.4107X50 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| K0155.410X60 | L | jet black | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.4105X60 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.4106X60 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.4107X60 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| K0155.4101X15 | L | jet black | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.41015X15 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.41016X15 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.41017X15 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.4101X20 | L | jet black | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.41015X20 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.41016X20 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.41017X20 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.4101X25 | L | jet black | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.41015X25 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.41016X25 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.41017X25 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.4101X30 | L | jet black | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.41015X30 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.41016X30 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.41017X30 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.4101X35 | L | jet black | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.41015X35 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.41016X35 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.41017X35 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.4101X40 | L | jet black | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.41015X40 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.41016X40 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.41017X40 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.4101X45 | L | jet black | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.41015X45 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.41016X45 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.41017X45 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.4101X50 | L | jet black | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.41015X50 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.41016X50 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.41017X50 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.4101X60 | L | jet black | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.41015X60 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.41016X60 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.41017X60 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.412X15 | L | jet black | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.4125X15 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.4126X15 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.4127X15 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| K0155.412X20 | L | jet black | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.4125X20 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.4126X20 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.4127X20 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| K0155.412X25 | L | jet black | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.4125X25 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.4126X25 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.4127X25 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| K0155.412X30 | L | jet black | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.4125X30 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.4126X30 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| K0155.4127X30 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| K0155.412X35 | L | jet black | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.4125X35 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.4126X35 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.4127X35 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| K0155.412X40 | L | jet black | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.4125X40 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.4126X40 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.4127X40 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| K0155.412X45 | L | jet black | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.4125X45 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.4126X45 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.4127X45 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| K0155.412X50 | L | jet black | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.4125X50 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.4126X50 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.4127X50 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| K0155.412X60 | L | jet black | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.4125X60 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.4126X60 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.4127X60 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| K0155.4102X20 | L | jet black | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.41025X20 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.41026X20 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.41027X20 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.4102X25 | L | jet black | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.41025X25 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.41026X25 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.41027X25 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.4102X30 | L | jet black | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.41025X30 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.41026X30 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.41027X30 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.4102X35 | L | jet black | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.41025X35 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.41026X35 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.41027X35 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.4102X40 | L | jet black | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.41025X40 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.41026X40 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.41027X40 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.4102X45 | L | jet black | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.41025X45 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.41026X45 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.41027X45 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.4102X50 | L | jet black | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.41025X50 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.41026X50 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.41027X50 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.4102X60 | L | jet black | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.41025X60 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.41026X60 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.41027X60 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.4121X20 | L | jet black | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.41215X20 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.41216X20 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.41217X20 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| K0155.4121X25 | L | jet black | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.41215X25 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.41216X25 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.41217X25 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| K0155.4121X30 | L | jet black | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |

Star grips similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| K0155.41215X30 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.41216X30 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.41217X30 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.4121X35 | L | jet black | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.41215X35 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.41216X35 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.41217X35 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.4121X40 | L | jet black | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.41215X40 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.41216X40 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.41217X40 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.4121X45 | L | jet black | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.41215X45 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.41216X45 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.41217X45 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.4121X50 | L | jet black | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.41215X50 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.41216X50 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.41217X50 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.4121X60 | L | jet black | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.41215X60 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.41216X60 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.41217X60 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.416X30 | L | jet black | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.4165X30 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.4166X30 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.4167X30 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| K0155.416X35 | L | jet black | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.4165X35 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.4166X35 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.4167X35 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| K0155.416X40 | L | jet black | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.4165X40 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.4166X40 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.4167X40 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| K0155.416X45 | L | jet black | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.4165X45 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.4166X45 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.4167X45 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| K0155.416X50 | L | jet black | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.4165X50 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.4166X50 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.4167X50 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| K0155.416X60 | L | jet black | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.4165X60 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.4166X60 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.4167X60 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| K0155.808 | S | jet black | - | 32 | 14 | 20 | 10 | - | 8 | - | 5 |
| K0155.810 | S | jet black | - | 40 | 18 | 25 | 13 | - | 10 | - | 10 |
| K0155.813 | S | jet black | - | 50 | 22 | 32 | 17 | - | 13 | - | 10 |
| K0155.816 | S | jet black | - | 63 | 26 | 40 | 21 | - | 16 | - | 15 |