

# Knurled knobs with grip

## Item description/product images




### Description


**Material:**  
Black thermoplastic.  
Bush grade 5.8 steel.

**Version:**  
Steel trivalent blue-passivated.

**Drawing reference:**  
Form H: without locking grub screw  
Form M: with locking grub screw

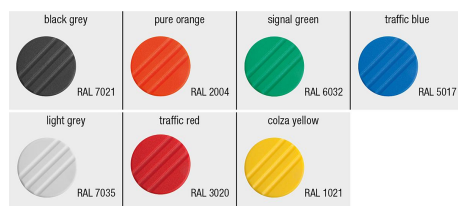

## Drawings

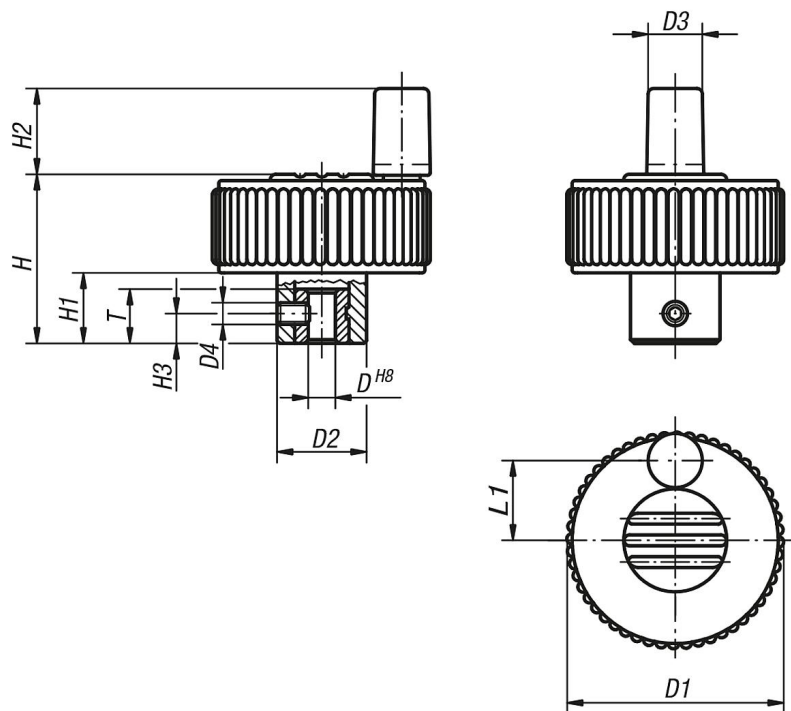

## Overview of items

### Knurled knobs with grip

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	L1	T
K0262.2106	H	black grey RAL 7021	6H8	40	16,5	10	-	31	13	16	-	15	10
K0262.21061	H	orange RAL 2004	6H8	40	16,5	10	-	31	13	16	-	15	10

## Knurled knobs with grip

### Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	L1	T
K0262.21062	H	signal green RAL6032	6H8	40	16,5	10	-	31	13	16	-	15	10
K0262.21063	H	blue RAL5017	6H8	40	16,5	10	-	31	13	16	-	15	10
K0262.21065	H	light grey RAL 7035	6H8	40	16,5	10	-	31	13	16	-	15	10
K0262.21066	H	traffic red RAL 3020	6H8	40	16,5	10	-	31	13	16	-	15	10
K0262.21067	H	colza yellow RAL 1021	6H8	40	16,5	10	-	31	13	16	-	15	10
K0262.2206	H	black grey RAL 7021	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.22061	H	orange RAL 2004	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.22062	H	signal green RAL6032	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.22063	H	blue RAL5017	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.22065	H	light grey RAL 7035	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.22066	H	traffic red RAL 3020	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.22067	H	colza yellow RAL 1021	6H8	50	18	10	-	36	15	16	-	18,5	10
K0262.2308	H	black grey RAL 7021	8H8	63	22	10	-	41	17	16	-	25	14
K0262.23081	H	orange RAL 2004	8H8	63	22	10	-	41	17	16	-	25	14
K0262.23082	H	signal green RAL6032	8H8	63	22	10	-	41	17	16	-	25	14
K0262.23083	H	blue RAL5017	8H8	63	22	10	-	41	17	16	-	25	14
K0262.23085	H	light grey RAL 7035	8H8	63	22	10	-	41	17	16	-	25	14
K0262.23086	H	traffic red RAL 3020	8H8	63	22	10	-	41	17	16	-	25	14
K0262.23087	H	colza yellow RAL 1021	8H8	63	22	10	-	41	17	16	-	25	14
K0262.1106	M	black grey RAL 7021	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.11061	M	orange RAL 2004	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.11062	M	signal green RAL6032	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.11063	M	blue RAL5017	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.11065	M	light grey RAL 7035	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.11066	M	traffic red RAL 3020	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.11067	M	colza yellow RAL 1021	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
K0262.1206	M	black grey RAL 7021	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.12061	M	orange RAL 2004	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.12062	M	signal green RAL6032	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.12063	M	blue RAL5017	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.12065	M	light grey RAL 7035	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.12066	M	traffic red RAL 3020	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.12067	M	colza yellow RAL 1021	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
K0262.1308	M	black grey RAL 7021	8H8	63	22	10	M4	41	17	16	8	25	14
K0262.13081	M	orange RAL 2004	8H8	63	22	10	M4	41	17	16	8	25	14
K0262.13082	M	signal green RAL6032	8H8	63	22	10	M4	41	17	16	8	25	14
K0262.13083	M	blue RAL5017	8H8	63	22	10	M4	41	17	16	8	25	14
K0262.13085	M	light grey RAL 7035	8H8	63	22	10	M4	41	17	16	8	25	14
K0262.13086	M	traffic red RAL 3020	8H8	63	22	10	M4	41	17	16	8	25	14
K0262.13087	M	colza yellow RAL 1021	8H8	63	22	10	M4	41	17	16	8	25	14