


Tube clamps T-angle aluminium

Item description/product images

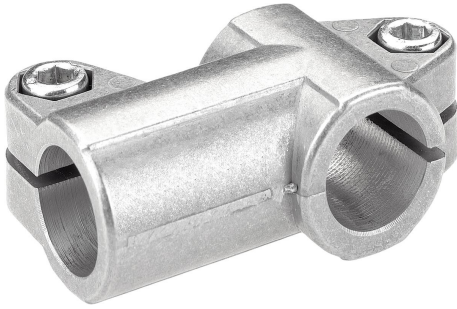

Description

Material:

Cast aluminium.
DIN 7984 screws and DIN 985 nuts, steel.

Version:


Vibratory ground.
Screws and nuts electro zinc-plated.

On request:

Lever for locking and other diameters.


Accessory:

- Round and square tubes K0493

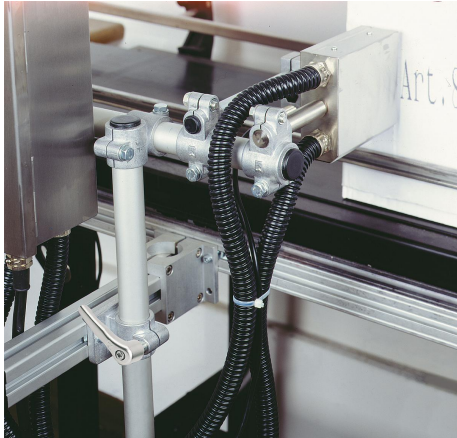


Tube clamps T-angle aluminium

Item description/product images

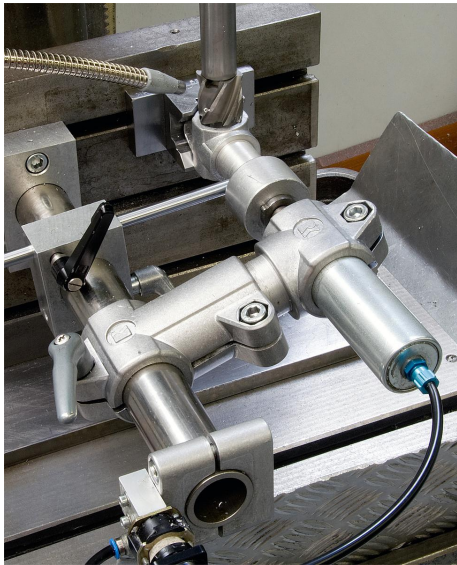

Drawings

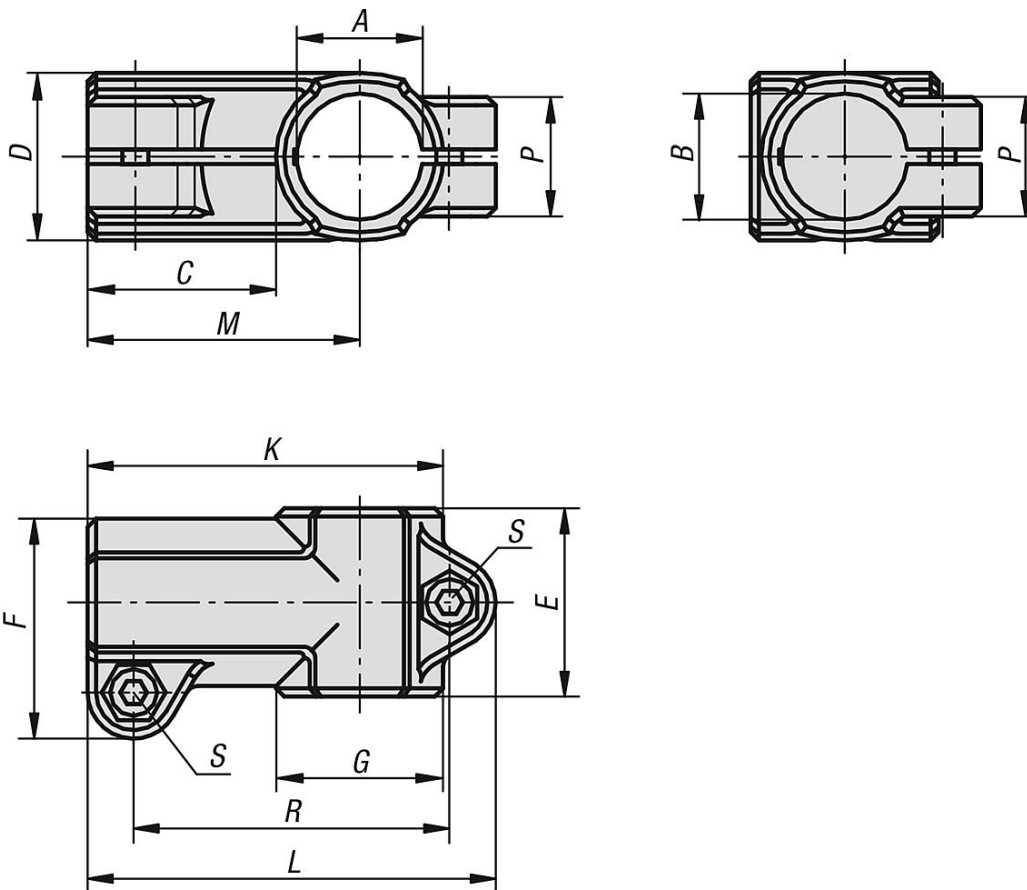

Overview of items

Tube clamps T-angle, aluminium

Tube clamps T-angle aluminium

Overview of items

Order No.	A	B	C	D	E	F	G	K	L	M	P	R	S
K0475.51212	12,1	12,1	28	25	32	35,5	25	56	66	43	23	49	M6x20
K0475.51414	14,1	14,1	28	25	32	35,5	25	56	66	43	23	49	M6x20
K0475.51515	15,1	15,1	28	25	32	35,5	25	56	66	43	23	49	M6x20
K0475.51616	16,1	16,1	28	25	32	35,5	25	56	66	43	23	49	M6x20
K0475.51818	18,1	18,1	28	25	32	35,5	25	56	66	43	23	49	M6x20
K0475.52020	20,1	20,1	38	40	45	53	40	80	93	60	33	72,5	M8x25
K0475.52525	25,1	25,1	38	40	45	53	40	80	93	60	33	72,5	M8x25
K0475.53030	30,1	30,1	38	40	45	53	40	80	93	60	33	72,5	M8x25
K0475.54040	40,15	40,15	55	56	60	74	56	116	134	88	40	108	M10x30
K0475.55050	50,22	50,22	63	66	66	84	66	131	149	98	45	123	M10x35