

## Clamping bolts

### Item description/product images



### Description

#### Version:

Clamping bolt, hardened and black oxidised.

Clamping ring, bright.

#### Note:


The clamping bolts can be fixed to the machine table directly with T-slot nuts.

Clamping parallel to the table is guaranteed by low tolerance classes (js6) for the height.

The clamping range is 8 – 40 mm. Clamping screws for the ranges 40 – 67 and 65 – 87 mm are also available.

The intermediate plate prevents damage to the machine table, as well as shifting during tightening. The brass clamping ring prevents impressions on the workpiece.

### Drawings

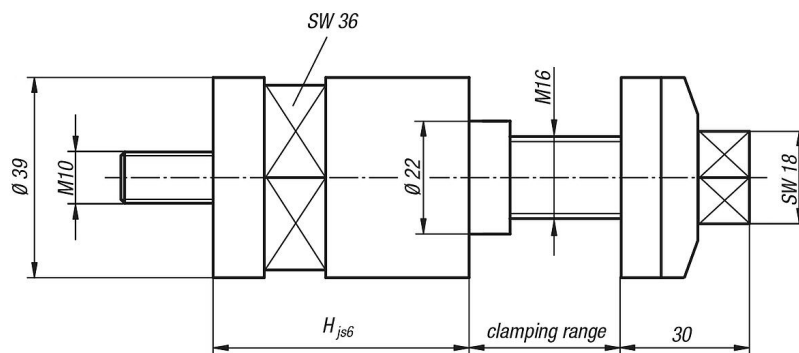

### Overview of items

Order No.	H	Clamp range
K1232.050	50	8-40
K1232.100	100	8-40