

# Plastic grips, round with rectangular opening

## Item description/product images




### Description

**Material:**  
Plastic

**Version:**  
Red, oil resistant.

**On request:**  
Other colours.

## Drawings

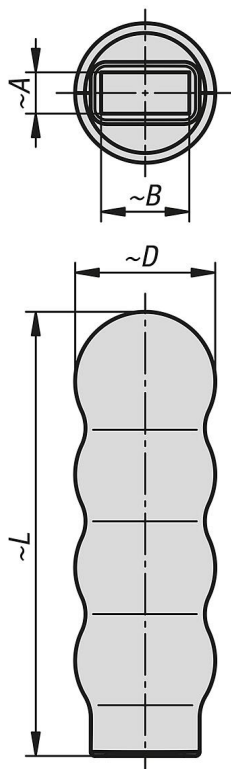

## Overview of items

### Plastic grips, round with rectangular opening

Order No.	A	B	D	L	for toggle clamp
K2110.034141	4	8	14	34	K1259.01000, K1255.010001, K1255.101000, K1255.001000, K1438.00800, K1436.00800, K1239.01000, K1434.00700
K2110.040154	5	9	15	40	K1547.01000, K1547.11000
K2110.043161	5	11	16	43	K1244.00800, K1255.101800, K1255.001800, K1254.1800, K1254.0800, K1432.02000, K1432.12000
K2110.057171	4	10	17	57	K1259.02000, K1255.101600, K1255.001600, K1246.01600, K1436.01600
K2110.059191	5	11	19	59	K1241.12500, K1241.02500, K1251.02400, K1248.02400, K1246.02400, K1255.102400, K1255.002400, K1239.02500, K1434.01400, K1546.02400,

## Plastic grips, round with rectangular opening

### Overview of items

Order No.	A	B	D	L	for toggle clamp
K2110.081241	6	14	24,5	81	K1241.03400, K1255.102600, K1255.002600, K1258.02600, K1433.03400, K1239.03400, K1435.01400, K1546.04000
K2110.083241	6	16	24,5	83	K1259.03600, K1255.003600, K1251.04000, K1258.04000, K1246.04000, K1255.104000, K1255.004000, K1437.03600, K1436.03000, K1440.03500,
K2110.086271	8	17	27	86	K1241.05000, K1255.040001, K1244.03400, K1258.04400, K1438.03400, K1433.05400, K1239.05400, K1435.02400
K2110.092271	9	17,5	27	92	K1241.06000, K1258.07000, K1248.07000, K1255.007000, K1244.04400, K1438.04400, K1239.06400, K1435.03000, K1440.07500, K1432.07000,
K2110.118341	9	24	34	118	K1258.08000, K1248.08000, K1255.008000, K1244.05400, K1438.05400